

# UJVMXMXAD

Base Product



Ultra Low Loss (ULL) OM5 MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 12-Fiber, Low Smoke Zero Halogen (LSZH)

## Product Classification

|                       |  |
|-----------------------|--|
| Regional Availability | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America |
| Portfolio             | CommScope®   |
| Product Type          | Fiber trunk cable assembly   |
| Product Brand         | SYSTIMAX ULL   |
| Ordering Note         | Not available in the United States or Canada   |

## General Specifications


|                              |                         |
|------------------------------|-------------------------|
| Color, boot A                | Black                   |
| Color, connector A           | Lime green              |
| Color, boot B                | Black                   |
| Color, connector B           | Lime green              |
| Construction Type            | Stranded                |
| Furcation Color              | Lime green              |
| Interface, Connector A       | MPO-12/UPC Male         |
| Interface, Connector B       | MPO-12/UPC Male         |
| Jacket Color                 | Lime green              |
| Polarity                     | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 12                      |
| Total Fibers, quantity       | 12                      |

## Dimensions

|                                  |          |
|----------------------------------|----------|
| Breakout Length                  | 33 in    |
| Cable Assembly Length Range (m)  | 3 – 999  |
| Cable Assembly Length Range (ft) | 10 – 999 |

# UJVMXMXAD

## Ordering Tree

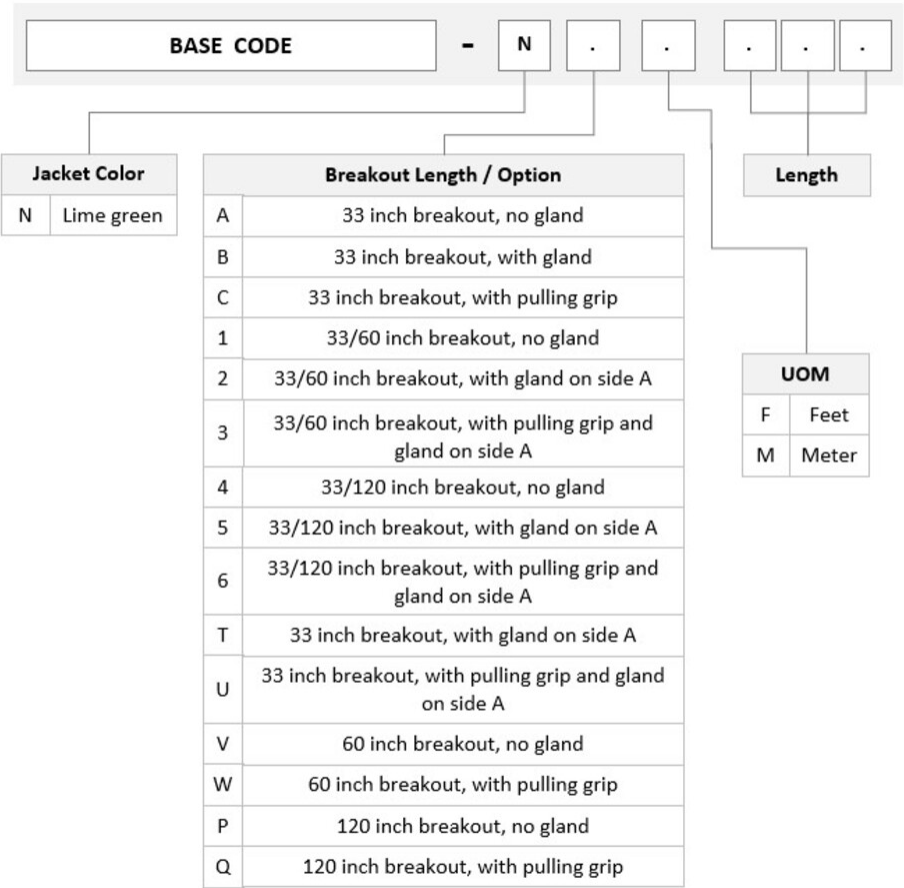

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Dual Rated LSZH/Riser | Indoor

# UJVMXMXAD

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



## Included Products

|                     |   |   |
|---------------------|---|---|
| 760229047           | – | Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber,  |
| N-012-MP-5G-F12LM/D |   | Gel-free, Multimode OM5, Dca Flame Rating, Feet jacket marking, Lime green jacket color |
| 860617240           | – | MP012, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm   |