


# UKGMPMXSW

Base Product

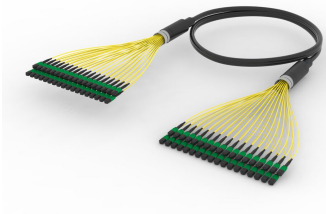

Ultra Low Loss Singlemode MPO12 Unpinned to MPO12 Pinned 576-Fiber Pre-terminated Trunk Cable, Rollable Ribbon Indoor/Outdoor Armored Central Tube, Low Smoke Zero Halogen/Riser

## Product Classification

Regional Availability	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration


## General Specifications

Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Armored   Rollable ribbon
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	MPO-12/APC Male
Jacket Color	Black
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	576

## Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

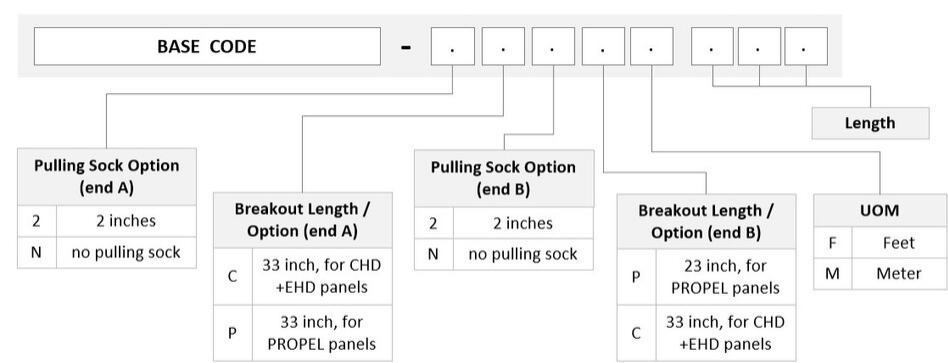

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode  
Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)  
Environmental Space Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



# UKGMPMXSW

---

## Included Products

- |                           |   |                                                                                              |
|---------------------------|---|----------------------------------------------------------------------------------------------|
| 760239051                 | – | Fiber indoor/outdoor cable, Interlocking Armored, LSZH Riser-Rated, Gel-Free, Central Tube   |
| Z-576-CZ-RR-F12BK/8G1/99G |   | Rollable Ribbon, 576 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Black jacket color, |
| /B2                       |   | B2ca flame rating                                                                            |
| 860638317                 | – | MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm                                          |
| 860638318                 | – | MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm                                        |