


# ULGLFLFCD

Base Product

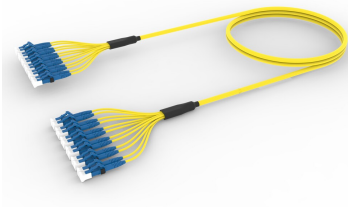

Ultra Low Loss ULL TeraSPEED® LC/UPC G B to LC/UPC G B  
Ruggedized fanout Cable, 12-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca

## Product Classification

|                       |  |
|-----------------------|--|
| Regional Availability | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| Portfolio             | CommScope®   |
| Product Type          | Ruggedized fanout  |
| Product Brand         | SYSTIMAX ULL   |
| Ordering Note         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                |                     |
|--------------------------------|---------------------|
| Color, boot A                  | Blue                |
| Color, connector A             | Green               |
| Color, boot B                  | Blue                |
| Color, connector B             | Blue                |
| Construction Type              | Stranded            |
| Furcation Color                | Yellow              |
| Interface, Connector A         | LC/UPC              |
| Interface Feature, connector A | Grade B performance |
| Interface, Connector B         | LC/UPC              |
| Interface Feature, connector B | Grade B performance |
| Jacket Color                   | Yellow              |
| Fibers per Subunit, quantity   | 12                  |
| Total Fibers, quantity         | 12                  |

## Dimensions

|                                  |         |
|----------------------------------|---------|
| Cable Assembly Length Range (m)  | 3 – 999 |
| Cable Assembly Length Range (ft) | 8 – 999 |

# ULGLFLFCD

## Optical Specifications

|            |                      |
|------------|----------------------|
| Fiber Mode | Singlemode           |
| Fiber Type | G.657.A2, TeraSPEED® |

## Environmental Specifications

|  |                                      |
|--|--------------------------------------|
| Operating Temperature                        | -10 °C to +60 °C (+14 °F to +140 °F) |
| EN50575 CPR Cable EuroClass Fire Performance | Dca                                  |
| Environmental Space                          | Indoor   Plenum                      |

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |



## Included Products

|                                    |   |
|------------------------------------|---|
| 760242049<br>P-012-MP-8G-F12YL/20T | – Fiber indoor cable, Plenum for MPO Trunks, 12 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color |
|------------------------------------|---|