


# ULVMPSCCL

## Base Product

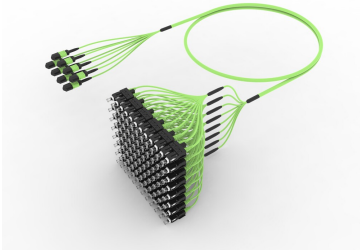

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Unpinned) to SC/UPC Ruggedized fanout Cable, 96-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                       |                         |
|---------------------------------------|-------------------------|
| <b>Color, boot A</b>                  | Black                   |
| <b>Color, connector A</b>             | Black                   |
| <b>Color, boot B</b>                  | Blue                    |
| <b>Color, connector B</b>             | Black                   |
| <b>Construction Type</b>              | Stranded                |
| <b>Furcation Color</b>                | Lime green              |
| <b>Interface, Connector A</b>         | MPO-12/UPC Female       |
| <b>Interface, Connector B</b>         | SC/UPC                  |
| <b>Interface Feature, connector B</b> | ULL                     |
| <b>Jacket Color</b>                   | Lime green              |
| <b>Polarity</b>                       | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b>   | 12                      |
| <b>Total Fibers, quantity</b>         | 96                      |

## Dimensions

|  |         |
|--|---------|
| <b>Cable Assembly Length Range (m)</b> | 3 – 999 |
|--|---------|



# ULVMPSCCL

---

|               |  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |



## Included Products

|                       |   |  |
|-----------------------|---|--|
| 760242123             | - | Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 96 fiber multi-unit with 12 fiber subunits, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color |
| P-096-MP-5G-F12LM/20T |   |  |
| 860659014             | - | MPO12, ULL, FEMALE, OM5, LIME, 2MM   |