


Base Product

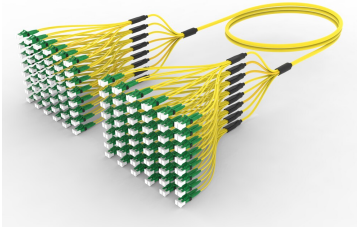

Ultra Low Loss ULL TeraSPEED® LC/APC G B to LC/APC G B
Ruggedized fanout Cable, 96-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Green
Color, connector A	Green
Color, boot B	Green
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	LC/APC
Interface Feature, connector A	Grade B performance
Interface, Connector B	LC/APC
Interface Feature, connector B	Grade B performance
Jacket Color	Yellow
Fibers per Subunit, quantity	12
Total Fibers, quantity	96

Dimensions

Cable Assembly Length Range (m)	3 – 999
--	---------

UNGLGLGCL

Cable Assembly Length Range (ft) 8 – 999

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance Dca

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

760242312 N-096-MP-8G-F12YL/20T/D	–	Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber multi-unit with 12 fiber 2.0mm subunits, Gel-free, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
--------------------------------------	---	--