


# UNGMXSACK

## Base Product

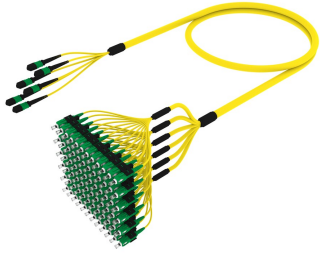

Ultra Low Loss ULL TeraSPEED® MPO(Pinned) to SC/APC Ruggedized fanout Cable, 72-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                       |                         |
|---------------------------------------|-------------------------|
| <b>Color, boot A</b>                  | Black                   |
| <b>Color, connector A</b>             | Green                   |
| <b>Color, boot B</b>                  | Green                   |
| <b>Color, connector B</b>             | Green                   |
| <b>Construction Type</b>              | Stranded                |
| <b>Furcation Color</b>                | Yellow                  |
| <b>Interface, Connector A</b>         | MPO-12/APC Male         |
| <b>Interface, Connector B</b>         | SC/APC                  |
| <b>Interface Feature, connector B</b> | ULL                     |
| <b>Jacket Color</b>                   | Yellow                  |
| <b>Polarity</b>                       | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b>   | 12                      |
| <b>Total Fibers, quantity</b>         | 72                      |

## Dimensions

|  |         |
|--|---------|
| <b>Cable Assembly Length Range (m)</b> | 3 – 999 |
|--|---------|

# UNGMXSACK

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree



## Optical Specifications

**Fiber Mode**

Singlemode

**Fiber Type**

G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance**

Dca

**Environmental Space**

Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

**Agency**

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system

# UNGMXSACK

---

## Included Products

- 2160441-2 - SC/APC Connector, Singlemode, Green
- 760242311  
N-072-MP-8G-F12YL/20T/D - Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 72 fiber multi-unit with 12 fiber 2.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
- 860659010 - MPO-12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm