


# UNVLULUCL

## Base Product

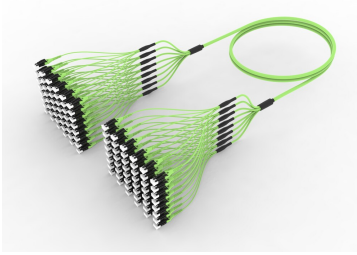

Ultra Low Loss ULL LazrSPEED® 550 OM5 LC/UPC Uniboot to LC/UPC Uniboot Ruggedized fanout Cable, 96-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Ruggedized fanout

### Product Brand

SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Blue

### Color, connector A

Black

### Color, boot B

Blue

### Color, connector B

Black

### Construction Type

Stranded

### Furcation Color

Lime green

### Interface, Connector A

LC/UPC

### Interface Feature, connector A

Uniboot

### Interface, Connector B

LC/UPC

### Interface Feature, connector B

Uniboot

### Jacket Color

Lime green

### Fibers per Subunit, quantity

12

### Total Fibers, quantity


96

## Dimensions

### Cable Assembly Length Range (m)

3 – 305

## Ordering Tree

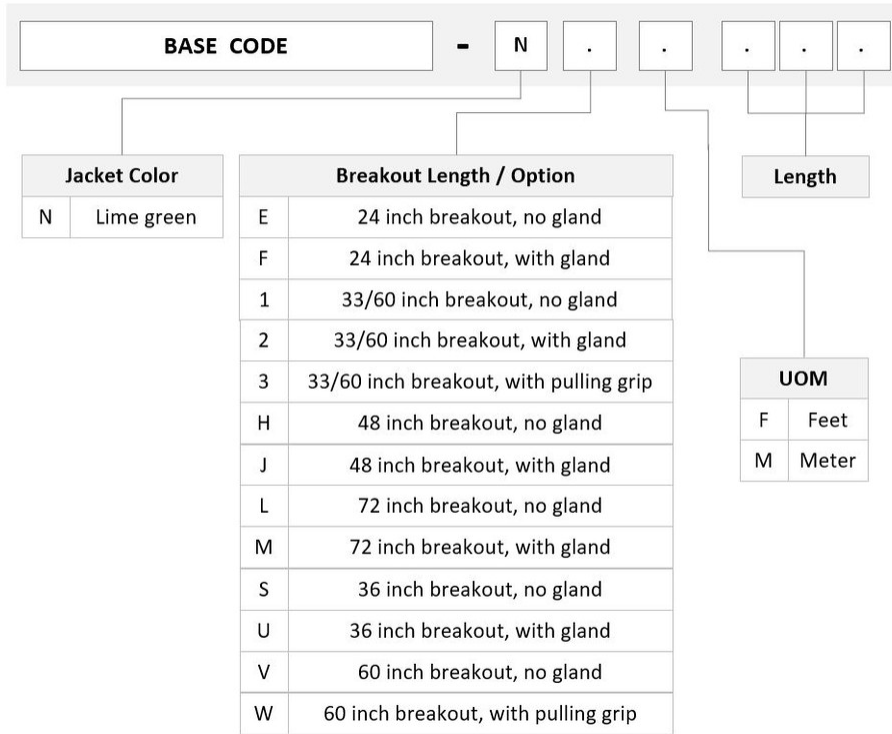

## Optical Specifications

- Fiber Mode** Multimode
- Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

- Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)
- EN50575 CPR Cable EuroClass Fire Performance** Dca
- Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

- | Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

# UNVLULUCL

---

REACH-SVHC Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS Compliant

UK-ROHS Compliant



## Included Products

- 760244160 N-096-MP-5G-F12LM/20T/D – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber multi-unit with 12 fiber 2.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, Dca flame rating