


Base Product

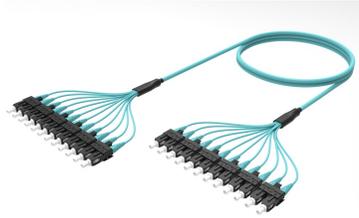

Ultra Low Loss ULL LazrSPEED® 550 SC/UPC to SC/UPC Ruggedized fanout Cable, 12-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand Europe Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Ruggedized fanout |
| Product Brand | SYSTIMAX ULL |
| Ordering Note | For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |


General Specifications

| | |
|---------------------------------------|----------|
| Color, boot A | Blue |
| Color, connector A | Black |
| Color, boot B | Blue |
| Color, connector B | Black |
| Construction Type | Stranded |
| Furcation Color | Aqua |
| Interface, Connector A | SC/UPC |
| Interface Feature, connector A | ULL |
| Interface, Connector B | SC/UPC |
| Interface Feature, connector B | ULL |
| Jacket Color | Aqua |
| Fibers per Subunit, quantity | 12 |
| Total Fibers, quantity | 12 |

Dimensions

| | |
|--|---------|
| Cable Assembly Length Range (m) | 3 – 305 |
|--|---------|

Ordering Tree

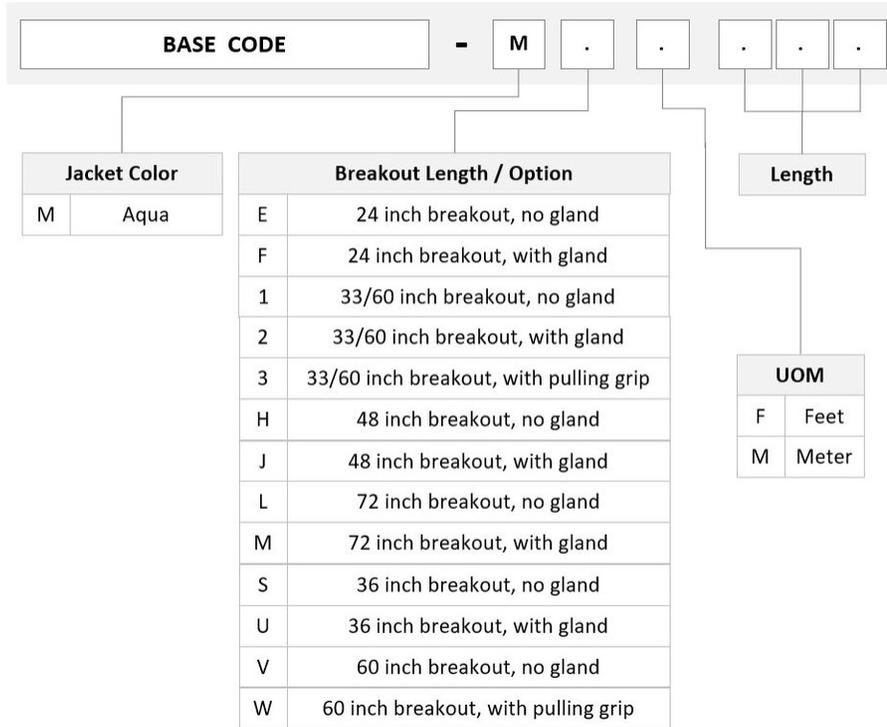

Optical Specifications

| | |
|-------------------|-----------------|
| Fiber Mode | Multimode |
| Fiber Type | OM4, LazrSPEED® |

Environmental Specifications

| | |
|---|--------------------------------------|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
| EN50575 CPR Cable EuroClass Fire Performance | Dca |
| Environmental Space | Dual Rated LSZH/Riser Indoor |

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|-----------------------------------|
| ANATEL | Compliant |
| CHINA-ROHS | Below maximum concentration value |

UNXSCSCCD

| | |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



Included Products

| | | |
|--------------------------------------|---|--|
| 760222844 N-012-MP-5K-F12AQ/20T/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk with 2.0mm Subunits, 12 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating |
|--------------------------------------|---|--|