


# A3XMPMXCH

## Base Product

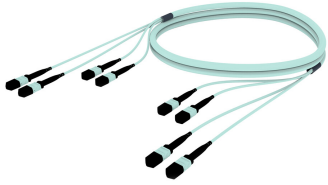

Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to MPO(Pinned)  
Pre-terminated Trunk Cable, MPO12, 48-Fiber, LSZH, 12 fiber PmP 2.0  
mm /B2ca, Method A

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Europe   Middle East/Africa  |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                   |
|-------------------------------------|-------------------|
| <b>Color, boot A</b>                | Black             |
| <b>Color, connector A</b>           | Black             |
| <b>Color, boot B</b>                | Black             |
| <b>Color, connector B</b>           | Black             |
| <b>Construction Type</b>            | Stranded          |
| <b>Furcation Color</b>              | Aqua              |
| <b>Interface, Connector A</b>       | MPO-12/UPC Female |
| <b>Interface, Connector B</b>       | MPO-12/UPC Male   |
| <b>Jacket Color</b>                 | Aqua              |
| <b>Polarity</b>                     | Method A          |
| <b>Fibers per Subunit, quantity</b> | 12                |
| <b>Total Fibers, quantity</b>       | 48                |

## Dimensions

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 33 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# A3XMPMXCH

## Ordering Tree

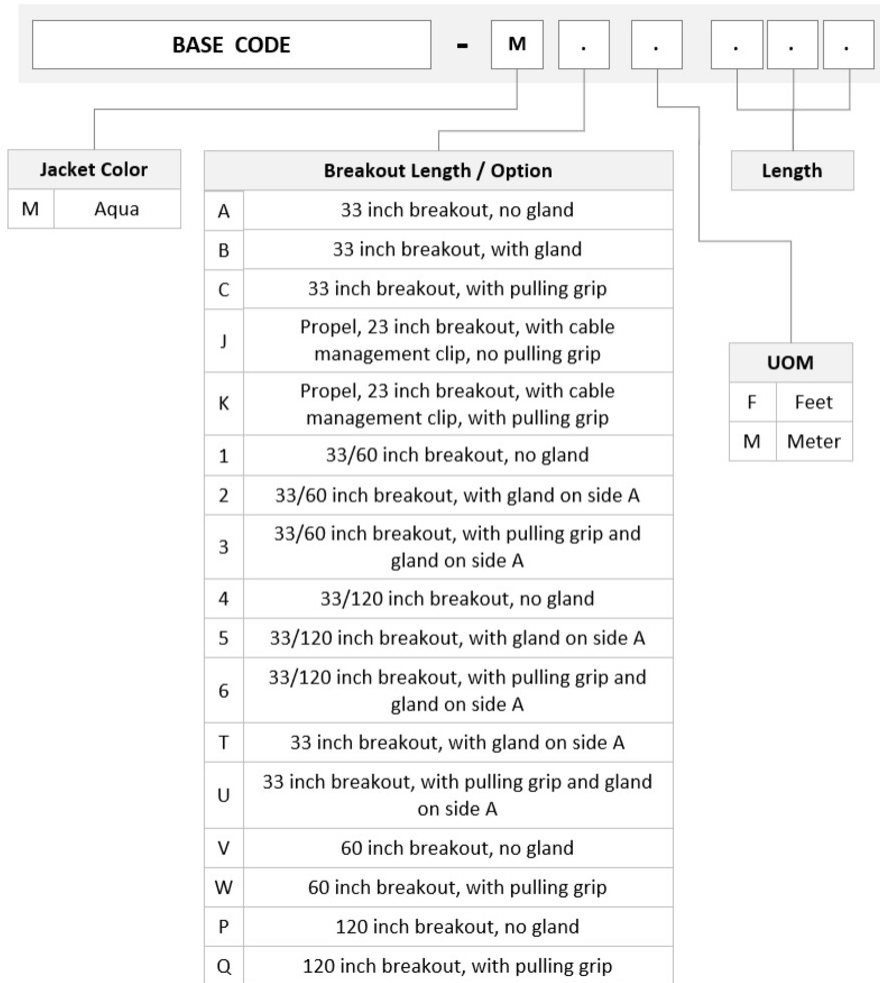

## Optical Specifications

|                   |                 |
|-------------------|-----------------|
| <b>Fiber Mode</b> | Multimode       |
| <b>Fiber Type</b> | OM4, LazrSPEED® |

## Environmental Specifications

|   |  |
|---|--|
| <b>Operating Temperature</b>                        | -10 °C to +60 °C (+14 °F to +140 °F)   |
| <b>EN50575 CPR Cable EuroClass Fire Performance</b> | B2ca                                   |
| <b>Environmental Space</b>                          | Indoor   Low Smoke Zero Halogen (LSZH) |

## Regulatory Compliance/Certifications

# A3XMPMXCH

---

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |

