

# AGGMXUCCG

## Base Product



Ultra Low Loss ULL TeraSPEED® MPO(Pinned) to Unconnectorized Pre-terminated Trunk Cable, MPO12, 36-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca, Method A

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                 |
|-------------------------------------|-----------------|
| <b>Color, boot A</b>                | Black           |
| <b>Color, connector A</b>           | Green           |
| <b>Construction Type</b>            | Stranded        |
| <b>Furcation Color</b>              | Yellow          |
| <b>Interface, Connector A</b>       | MPO-12/APC Male |
| <b>Interface, Connector B</b>       | Unterminated    |
| <b>Jacket Color</b>                 | Yellow          |
| <b>Polarity</b>                     | Method A        |
| <b>Fibers per Subunit, quantity</b> | 12              |
| <b>Total Fibers, quantity</b>       | 36              |

## Dimensions

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 33 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

## Ordering Tree

# AGGMXUCCG

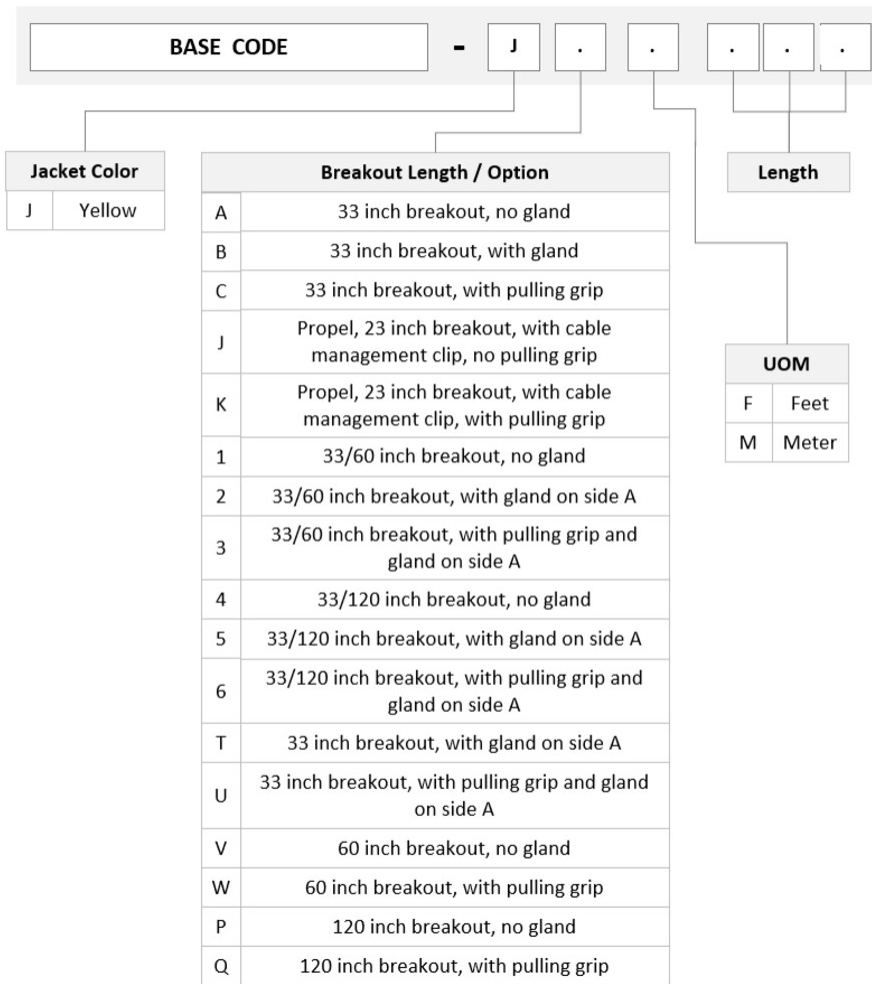

## Optical Specifications

|                   |                      |
|-------------------|----------------------|
| <b>Fiber Mode</b> | Singlemode           |
| <b>Fiber Type</b> | G.657.A2, TeraSPEED® |

## Environmental Specifications

|   |                                      |
|---|--------------------------------------|
| <b>Operating Temperature</b>                        | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>EN50575 CPR Cable EuroClass Fire Performance</b> | Dca                                  |
| <b>Environmental Space</b>                          | Indoor   Plenum                      |

## Regulatory Compliance/Certifications

|               |                       |
|---------------|-----------------------|
| <b>Agency</b> | <b>Classification</b> |
| ANATEL        | Compliant             |

# AGGMXUCCG

---

|               |  |
|---------------|--|
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



## Included Products

|                                    |   |   |
|------------------------------------|---|---|
| 760242053<br>P-036-MP-8G-F12YL/20T | - | Fiber indoor cable, Plenum MPO Trunk, 36 fiber multi-unit with 12 fiber subunits, Singlemode G. 657.A2/B2, Feet jacket marking, Yellow jacket color |
| 860659010                          | - | MPO-12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm  |