


# AGX2P2PBF

## Base Product

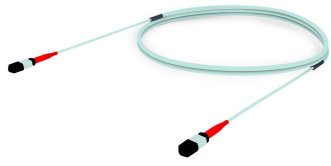

OM4 MPO24 (Unpinned) to MPO24 (Unpinned), Fiber Trunk Cable Assembly, 24-Fiber, Method A, Plenum

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Red

### Color, connector A

Aqua

### Color, boot B

Red

### Color, connector B

Aqua

### Construction Type

Stranded

### Furcation Color

Aqua

### Interface, Connector A

MPO-24/UPC Female

### Interface, Connector B

MPO-24/UPC Female

### Jacket Color

Aqua

### Polarity

Method A

### Fibers per Subunit, quantity

24

### Total Fibers, quantity

24

## Dimensions

### Cable Assembly Length Range (m)

3 – 999

### Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

# AGX2P2PBF



## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

## Regulatory Compliance/Certifications

# AGX2P2PBF

---

## Agency

CHINA-ROHS  
ISO 9001:2015  
REACH-SVHC  
ROHS  
UK-ROHS

## Classification

Above maximum concentration value  
Designed, manufactured and/or distributed under this quality management system  
Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)  
Compliant/Exempted  
Compliant/Exempted



## Included Products

- 760245199  
P-024-MP-5K-F30AQ
  - 860662277
- Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 24 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color
  - MPO24,FEMALE,OM3/4,AQUA,3.0MM