


FDXKNKN42

Base Product

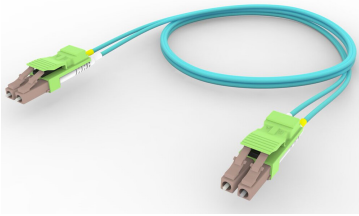

OM4 LC/UPC to LC/UPC Fiber Patch Cord, 1.6 mm Duplex, Plenum, Lime Green (AC) Locking Clip

Product Classification

Regional Availability	Asia Australia/New Zealand Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FDX
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	White
Color, connector A	Beige
Color, boot B	White
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Method B
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.6 mm 0.063 in

Ordering Tree

FDXKNKN42

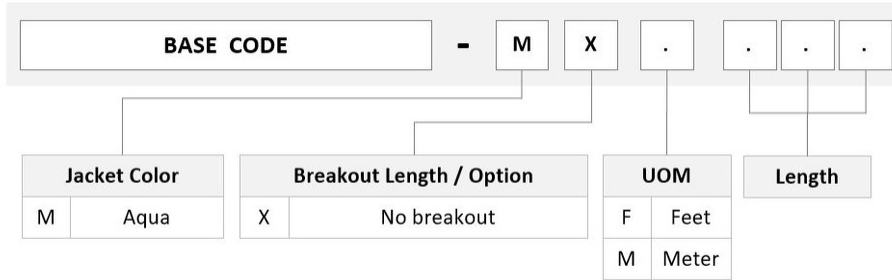

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Plenum

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

ROHS

UK-ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant

Compliant



Included Products

- | | |
|-----------------|--|
| 460125198 | - Pre-Radiused LC Connector duplex for 1.6 mm Fiber, multimode |
| P-002-ZC-5K-F16 | - Fiber indoor cable, LazrSPEED® 1.6 mm Plenum Zipcord, Multimode OM4, Feet jacket marking |