


# FDXL9SC42

## Base Product

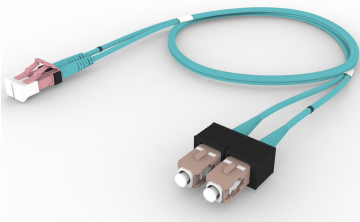

OM4 LC/UPC Keyed Rose to SC/UPC Fiber Patch Cord, 1.6 mm Duplex, Plenum

## Product Classification

Regional Availability	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FDX
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Aqua
Color, connector A	Rose
Color, boot B	Aqua
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface Feature, connector A	Keyed
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Polarity	Method B
Total Fibers, quantity	2

## Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.6 mm   0.063 in

# FDXL9SC42

## Ordering Tree



## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Plenum

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ANATEL	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



## Included Products

- |                 |   |   |
|-----------------|---|---|
| 460125750       | – | LazrSPEED® Pre-Radiused SC Connector for 1.6 mm Fiber Cordage, Duplex, multimode                |
| 760102483       | – | LazrSPEED®, OptiSPEED® Pre-Radiused Keyed LC Connector for 1.6 mm Fiber, duplex multimode, rose |
| MDC-LCR-16-KRO  |   |   |
| P-002-ZC-5K-F16 | – | Fiber indoor cable, LazrSPEED® 1.6 mm Plenum Zipcord, Multimode OM4, Feet jacket marking        |