


FNXLCLCAF

Base Product

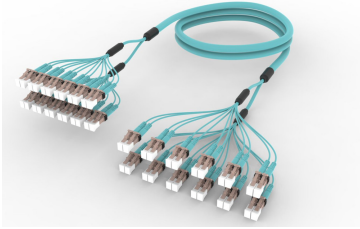

OM4 LC/UPC to LC/UPC 24-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Color, boot A

Aqua

Color, connector A

Beige

Color, boot B

Aqua

Color, connector B

Beige

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

LC/UPC

Interface, Connector B

LC/UPC

Jacket Color

Aqua

Fibers per Subunit, quantity

12

Total Fibers, quantity

24

Dimensions

Cable Assembly Length Range (m)


3 – 305

Cable Assembly Length Range (ft)

8 – 999

Ordering Tree

FNXLCLCAF

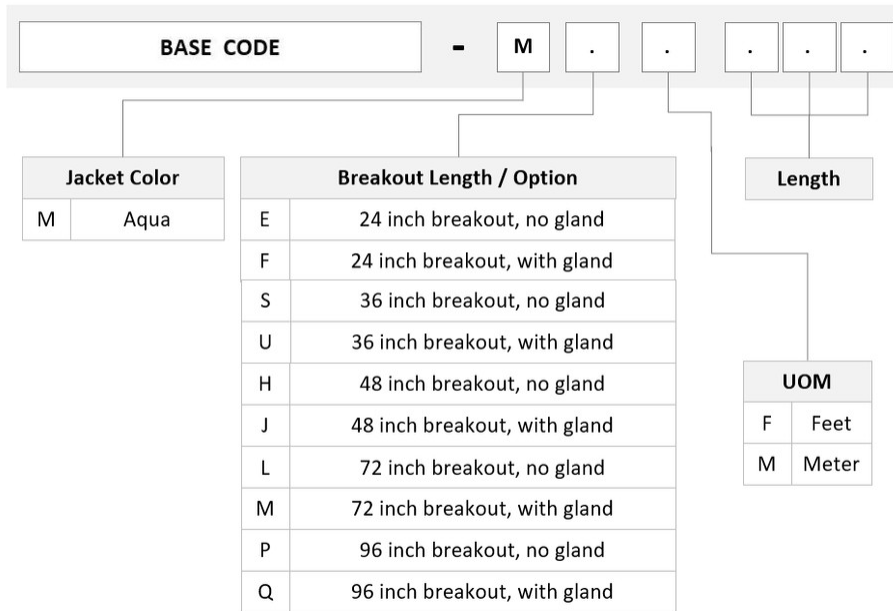

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

FNXLCLCAF



Included Products

- 760067488
N-024-MP-5K-F12AQ/D
 - Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 24 fiber with 12 fiber subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating
- 860637378
 - LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode