


FNZLCLCAH

Base Product

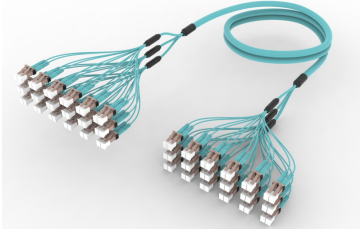

LazrSPEED® 300 LC/UPC to LC/UPC, InstaPATCH® 360 Ruggedized Fanout Cable, 48-Fiber, LSZH

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Color, connector A

Beige

Color, connector B

Beige

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

LC/UPC

Interface, Connector B

LC/UPC

Jacket Color

Aqua

Fibers per Subunit, quantity

12

Total Fibers, quantity

48

Dimensions

Cable Assembly Length Range (m)

3 – 305

Cable Assembly Length Range (ft)

7 – 999

Ordering Tree

FNZLCLCAH



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM3, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

460125198

- Pre-Radiused LC Connector duplex for 1.6 mm Fiber, multimode

N-048-MP-5L-F12

- Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Gel-free, Multimode OM3, Feet jacket marking, Dca flame rating