


# UQV2XLCHF

Base Product

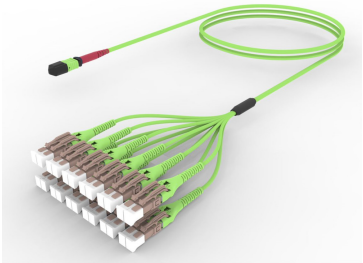

Ultra Low Loss (ULL) LazrSPEED® 550 WideBand OM5 MPO/24 (Pinned) to LC/UPC, 24-Fiber, Plenum

## Product Classification

Regional Availability	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Red
Color, connector A	Lime green
Color, boot B	Lime green
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	LC/UPC
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	24
Total Fibers, quantity	24


## Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999

# UQV2XLCHF

Cable Assembly Length Range (ft) 10 – 999

## Ordering Tree

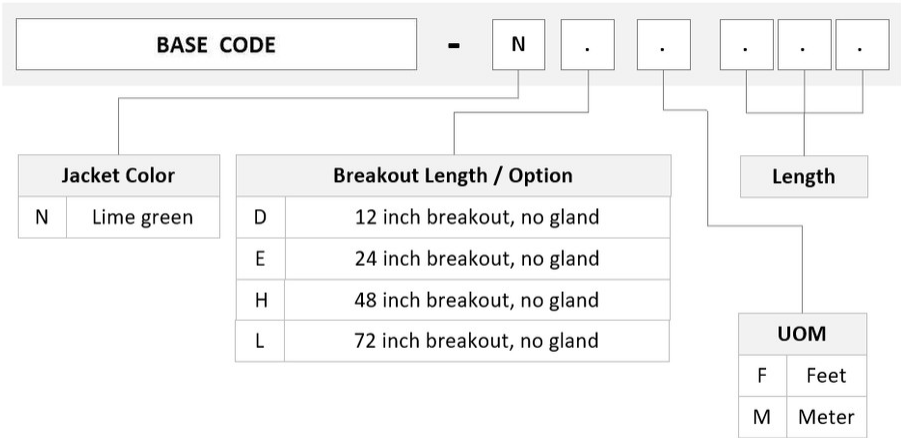

## Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

Fiber Mode Multimode  
Fiber Type OM5, LazrSPEED®

## Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)  
Environmental Space Indoor | Plenum

## Regulatory Compliance/Certifications

Agency Classification  
ISO 9001:2015 Designed, manufactured and/or distributed under this quality management system

## Included Products

- 760235986 P-024-MP-5G-F36LM – Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 24 fiber, Multimode OM5, Feet jacket marking, Lime green jacket color
- 860634625 – LazrSPEED® Elite MPO Male 24 Fiber Connector, lime green
- 860649627

# UQV2XLCHF

COMMSCOPE

– LC/UPC Connector, Multimode, Beige, Short Boot