


UQXMXLCGD

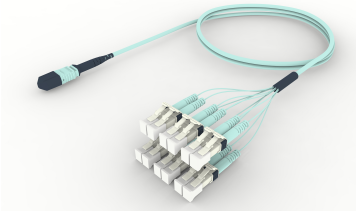

Ultra Low Loss (ULL) OM4 MPO12 (Pinned) to LC/UPC, Fiber Extension Cable Assembly, 12-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Aqua
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
Cable Assembly Length Range (m)	1 – 304
Cable Assembly Length Range (ft)	2 – 999

UQXMXLCGD

Ordering Tree

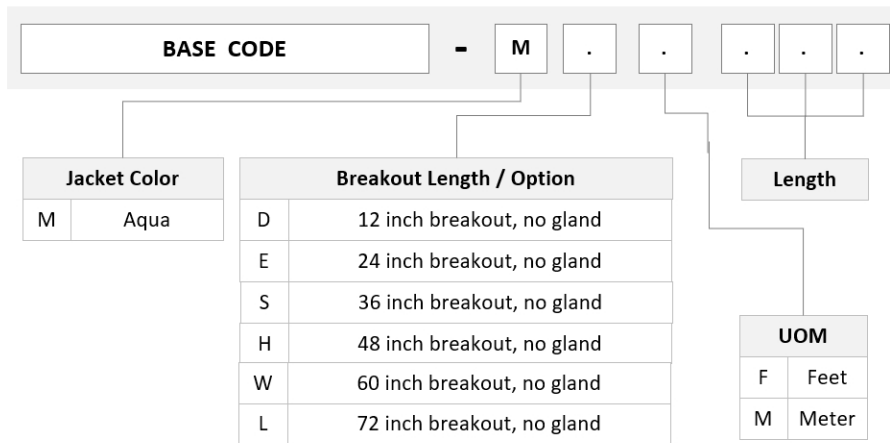

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015

Classification

Compliant

Designed, manufactured and/or distributed under this quality management system



Included Products

760074997

P-012-MP-5K-F30A0

- Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 12 fiber, Multimode

UQXMXLCGD

CONNECTORS

- 860366228 – OM4, Feet jacket marking, Aqua jacket color
- 860637425 – MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm
- LC/UPC Connector, Multimode, Beige, Short Boot