


# URGMPLUHF

Base Product

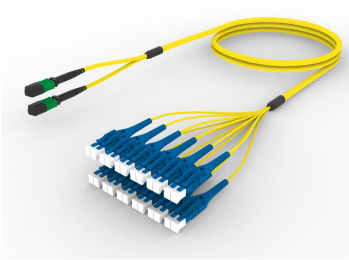

Ultra Low Loss Singlemode MPO12 Unpinned to LC/UPC Uniboot 24-Fiber Low Smoke Zero Halogen Riser Array Cord

## Product Classification

Regional Availability	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


Color, boot A	Red
Color, connector A	Green
Color, boot B	Blue
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	24
Total Fibers, quantity	24

# URGMPLUHF

## Dimensions

Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	3 – 999

## Ordering Tree

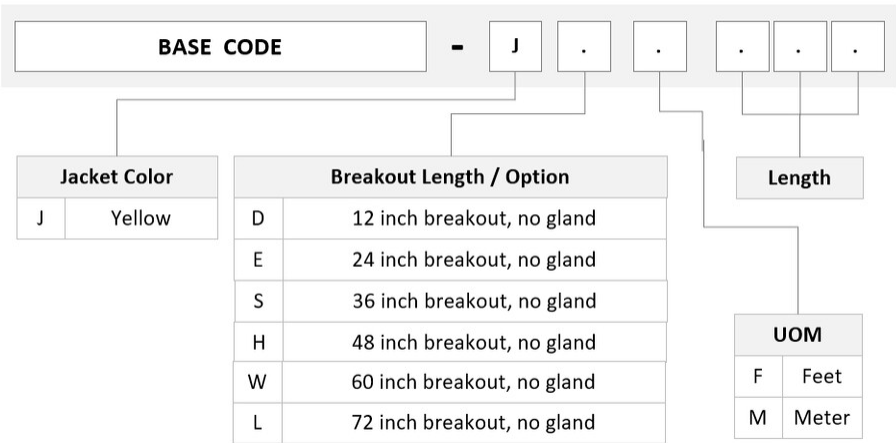

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor   Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# URGMPLUHF

---

ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760238981	–	Low Smoke Zero Halogen Riser MPO Trunk Cable, 24 fiber
N-024-MP-8G-F24YL/D		
860638318	–	MP012, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm
860658160	–	LC/UPC Uniboot Connector, Singlemode, Blue