


URVQPLCJ8

Base Product

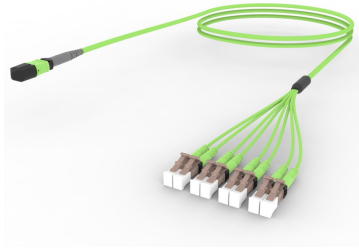

Ultra Low Loss OM5 MPO8 Unpinned to LC/UPC 8-Fiber Low Smoke Zero Halogen Array Cord

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Gray
Color, connector A	Lime green
Color, boot B	Lime green
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	LC/UPC
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8

Dimensions


Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999

URVQPLCJ8

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

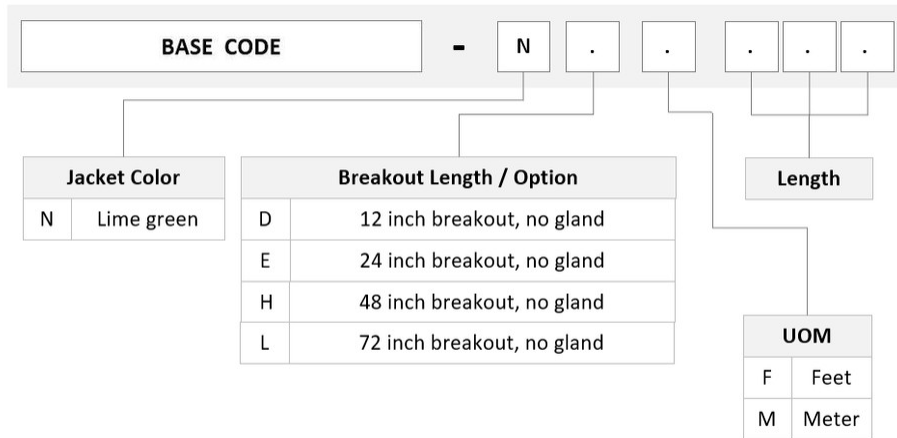

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM5, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency

Classification

ANATEL

Compliant

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

URVQPLCJ8



Included Products

- | | | |
|----------------------------------|---|--|
| 760229039
N-012-MP-5G-F30LM/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO Patchcords, 12 fiber, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color, Dca Flame rating |
| 860633311 | - | MPO8, ULTRA LOW LOSS, FEMALE, OM5, LIME, 3mm |
| 860649627 | - | LC/UPC Connector, Multimode, Beige, Short Boot |