

# URXMPMXGD

## Base Product



Ultra Low Loss (ULL) OM4 MPO12 (Unpinned) to MPO12 (Pinned), Fiber Extension Cable Assembly, 12-Fiber, Low Smoke Zero Halogen

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America  |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber array cable assembly   |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Color, boot A</b>                | Black                   |
| <b>Color, connector A</b>           | Aqua                    |
| <b>Color, boot B</b>                | Black                   |
| <b>Color, connector B</b>           | Aqua                    |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Aqua                    |
| <b>Interface, Connector A</b>       | MPO-12/UPC Female       |
| <b>Interface, Connector B</b>       | MPO-12/UPC Male         |
| <b>Jacket Color</b>                 | Aqua                    |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 12                      |
| <b>Total Fibers, quantity</b>       | 12                      |

## Dimensions

|   |         |
|---|---------|
| <b>Breakout Length</b>                  | 33 in   |
| <b>Cable Assembly Length Range (m)</b>  | 1 – 305 |
| <b>Cable Assembly Length Range (ft)</b> | 1 – 999 |

# URXMPMXGD

## Ordering Tree

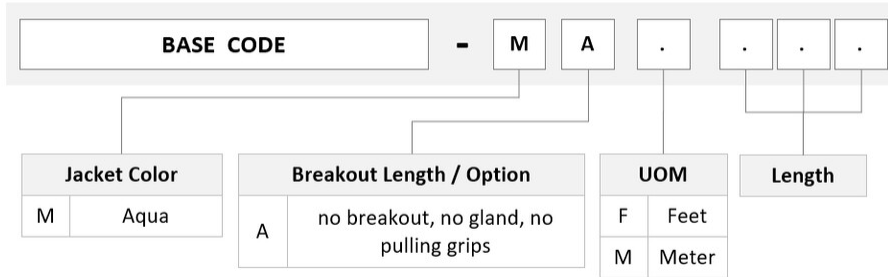

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



## Included Products

760102178 – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO

# URXMPMXGD

---

|                     |   |   |
|---------------------|---|---|
| N-012-MP-5K-F30AQ/D |   | Patchcords, 12 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860366210           | - | MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm   |
| 860366228           | - | MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm   |