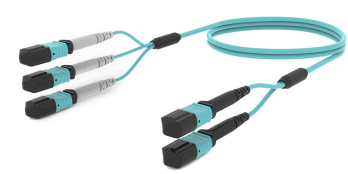# URXQPMPHF

Base Product

Ultra Low Loss OM4, MPO8 QSFP (Unpinned) to MPO12 (Unpinned), Fiber Extension Cable Assembly, 24-Fiber, Low Smoke Zero Halogen

Product Classification

Regional Availability	Australia/New Zealand	Europe	Latin America	Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative	For lengths greater than 999 ft (304 m), orders must be in meters	Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Gray
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Female
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	24

Dimensions

Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	1 – 999

COMMSCOPE®

URXQPMPHF

Ordering Tree

BASE CODE	-	M	.	.	.	.	.

Jacket Color

M	Aqua

Breakout Length / Option

D	12 inch breakout, no gland
E	24 inch breakout, no gland
S	36 inch breakout, no gland
H	48 inch breakout, no gland
L	72 inch breakout, no gland
P	96 inch breakout, no gland

Length

UOM

F	Feet
M	Meter

Mechanical Specifications

Cable Retention Strength, maximum   11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode   Multimode

Fiber Type   OM4, LazrSPEED®

Environmental Specifications

Operating Temperature   -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space   Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

ANATEL

Included Products

760256685
N-024-MP-5K-F30AQ/D   –   Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO
Patchcords, 24 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca

COMMSCOPE®

flame rating

| 860366210 | – | MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm |
| 860633307 | – | MPO8, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm |

COMMSCOPE®