


ANXMPLCAD

Base Product

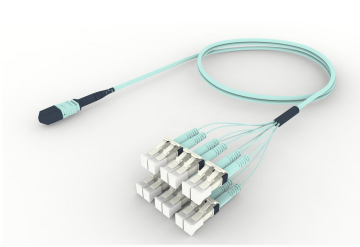

OM4 MPO12 (Unpinned) to LC, Ruggedized Fanout Fiber Cable, 12-Fiber, Method A, Low Smoke Zero Halogen

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Black

Color, connector A

Aqua

Color, boot B

Aqua

Color, connector B

Beige

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

MPO-12/UPC Female

Interface, Connector B

LC/UPC

Jacket Color

Aqua

Polarity

Method A

Fibers per Subunit, quantity

12

Total Fibers, quantity

12

Dimensions

Cable Assembly Length Range (m)


3 – 999

Cable Assembly Length Range (ft)

7 – 999

ANXMPLCAD

Ordering Tree

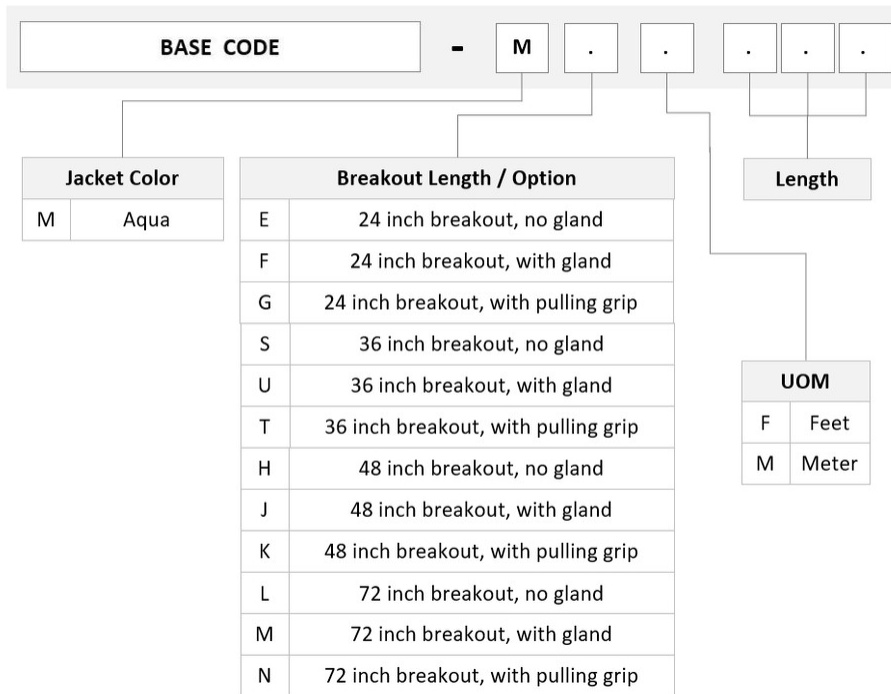

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value

ANXMPLCAD

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

760067470	-	Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber, Gel-free, Multimode OM4, Dca Flame Rating, Feet jacket marking, Aqua jacket color
N-012-MP-5K-F12AQ/D		
860366210		
860637378	-	MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
	-	LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode