

DFJ-2S5-HW



HELIAX® Discrete, 2 single mode fiber, 5 mm LSZH cable. End 1: DLC.
End 2: DLC Breakout length: end one, 72mm. Breakout length: end two, 382mm.

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFJ
Ordering Note	ANDREW® non-standard product

General Specifications


Construction Type	Discrete fiber tail
Interface, Connector A	DLC
Interface Body Style, connector A	Straight
Interface, Connector B	DLC
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	2

Dimensions

Breakout Length, connector A	72 mm 2.835 in
Breakout Length, connector B	72 mm 2.835 in
Cable Assembly Length Range (m)	1 – 200
Diameter Over Jacket	4.8 mm 0.189 in

Ordering Tree

DFJ-2S5-HW

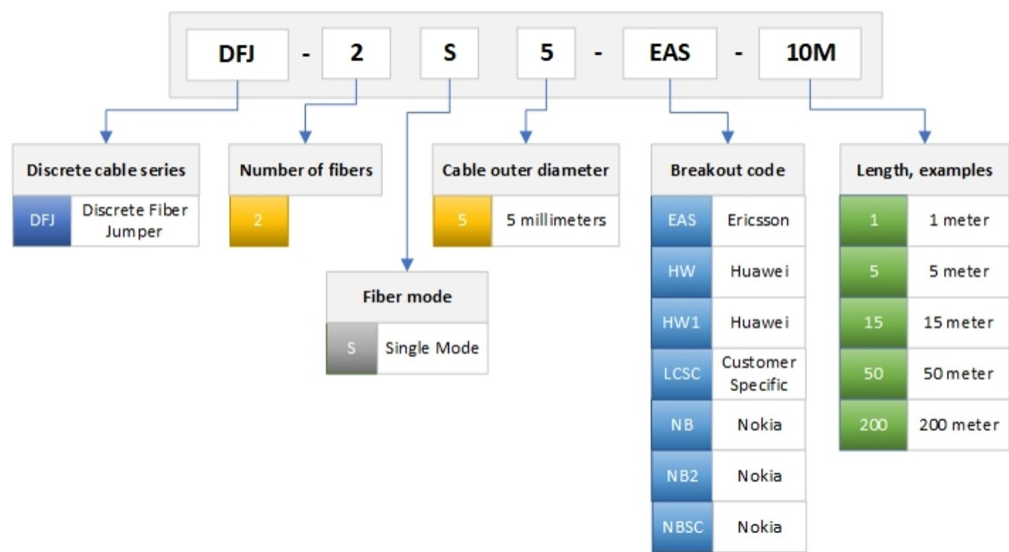

Material Specifications

Jacket Material Low Smoke Zero Halogen (LSZH)

Mechanical Specifications

Minimum Bend Radius, furcation 10 mm | 0.394 in

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2

Insertion Loss, typical note Insertion loss is measured at 1310 and 1550 nm

Insertion Loss, typical 0.5

Environmental Specifications

Operating Temperature -40 °C to +80 °C (-40 °F to +176 °F)

Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Cable weight 24 kg/km | 16.127 lb/kft

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

DFJ-2S5-HW

* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)