

# DFJ-2S5-NB



HELIAX® Discrete, 2 single mode fiber, 5 mm LSZH cable. End 1: DLC with weatherproofing boot. End 2: DLC with weatherproofing boot

## Product Classification

Regional Availability	Asia   Australia/New Zealand   EMEA   Latin America   North America
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFJ
Ordering Note	ANDREW® non-standard product

## General Specifications


Construction Type	Discrete fiber tail
Interface, Connector A	DLC
Interface Feature, connector A	Nokia boot
Interface Body Style, connector A	Straight
Interface, Connector B	DLC
Interface Feature, connector B	Nokia boot
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	2

## Dimensions

Cable Assembly Length Range (m)	1 – 200
Diameter Over Jacket	4.8 mm   0.189 in

## Ordering Tree

# DFJ-2S5-EAS-10M

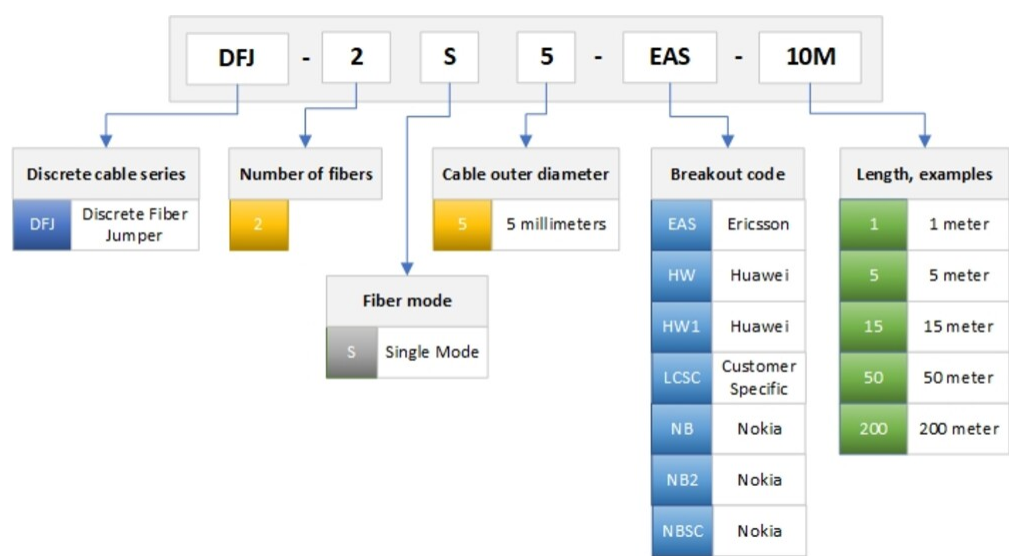

## Material Specifications

**Jacket Material** Low Smoke Zero Halogen (LSZH)

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2

**Insertion Loss, typical note** Insertion loss is measured at 1310 and 1550 nm

**Insertion Loss, typical** 0.5

## Environmental Specifications

**Operating Temperature** -40 °C to +80 °C (-40 °F to +176 °F)

**Environmental Space** Outdoor

## Packaging and Weights

**Cable weight** 24 kg/km | 16.127 lb/kft

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

## \* Footnotes

**Insertion Loss, typical note** Insertion loss is measured at a room temp of +20°C (+68°F)

