

DFJ-6S025

HELIAX® Direct tail, 6 Single mode fiber, armored, End 1: DLC for BBU.
End 2: DLC for Junction box



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFJ
Ordering Note	CommScope® non-standard product

General Specifications


Construction Type	Discrete fiber tail
Interface, Connector A	DLC
Interface Body Style, connector A	Straight
Interface, Connector B	DLC
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	6

Dimensions

Cable Assembly Length Range (ft)	6 – 100
Diameter Over Jacket	8 mm 0.315 in

Ordering Tree

DFJ-6S025

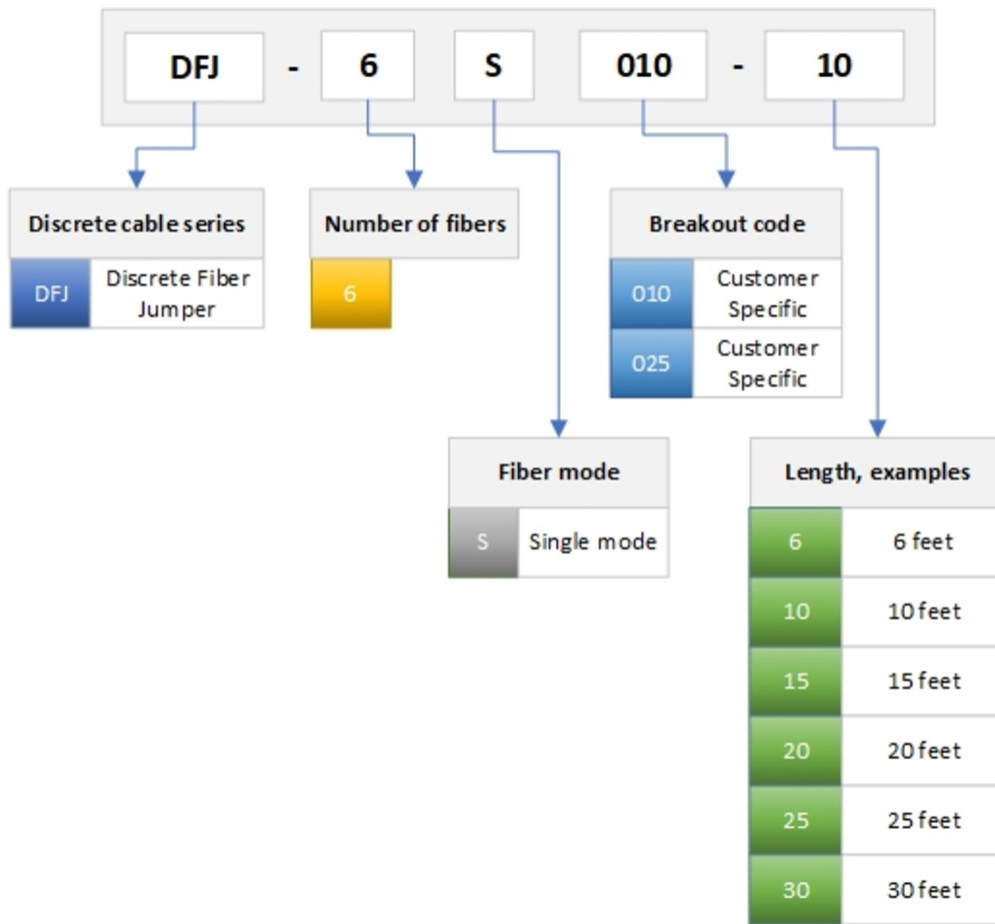

Optical Specifications

Fiber Type	G.657.A2
Insertion Loss, typical note	Insertion loss is measured at 1310 and 1550 nm
Insertion Loss, typical	0.5

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Indoor

Packaging and Weights

Cable weight	69 kg/km 46.366 lb/kft
---------------------	--------------------------

Regulatory Compliance/Certifications

Agency	Classification
---------------	-----------------------

DFJ-6S025

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)