


FEXL2LC21

Base Product

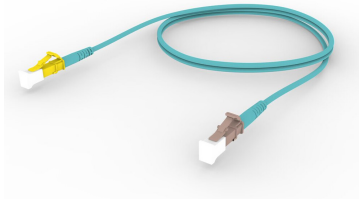

OM4 LC/UPC Keyed Yellow to LC/UPC Fiber Patch Cord, 1.6 mm Simplex, Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FEX
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Aqua
Color, connector A	Yellow
Color, boot B	Aqua
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface Feature, connector A	Keyed
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Method B
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.6 mm 0.063 in

FEXL2LC21

Ordering Tree

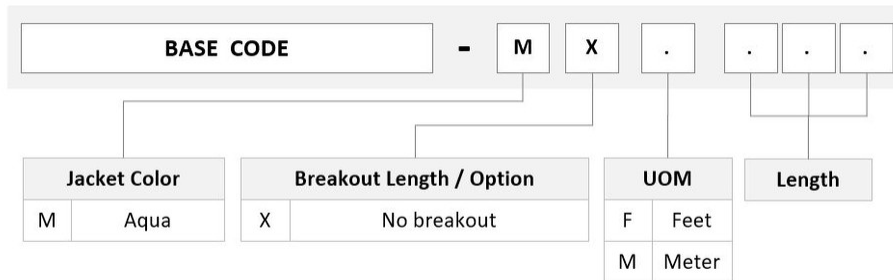

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Riser

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015

Classification

Compliant

Designed, manufactured and/or distributed under this quality management system



Included Products

- 460125172 – Pre-Radiused LC Connector simplex for 1.6 mm Fiber, multimode
- 760102350
MFC-LCR-16-KYL – LazrSPEED®, OptiSPEED® Pre-Radiused Keyed LC Connector for 1.6 mm Fiber, simplex multimode, yellow
- R-001-SP-5K-F16 – Fiber indoor cable, LazrSPEED® 1.6 mm Riser Simplex, Multimode OM4, Feet jacket marking