


FEXLCSC21

Base Product

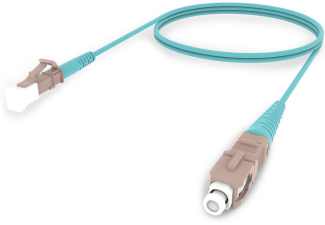

OM4 LC/UPC to SC/UPC Fiber Patch Cord, 1.6 mm Simplex, Riser

Product Classification

Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East /Africa | North America

Portfolio

CommScope®

Product Type

Fiber patch cord, simplex

Product Brand

SYSTIMAX InstaPATCH® 360

Product Series

FEX

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Aqua
Color, connector A	Black
Color, boot B	Aqua
Color, connector B	Black
Interface, Connector A	LC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Polarity	Method B
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.6 mm 0.063 in

Ordering Tree

FEXLCSC21



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Riser

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

460125172	- Pre-Radiused LC Connector simplex for 1.6 mm Fiber, multimode
460125735	- LazrSPEED® Pre-Radiused SC Connector for 1.6 mm Fiber Cordage, Simplex, multimode
760010595	- Fiber indoor cable, LazrSPEED® 1.6 mm Riser Zipcord, Multimode OM4, Feet jacket marking,
R-002-7C-5K-F16A0	

FEXLCSC21

1002 20 011 1014

Aqua jacket color