


2105091-3

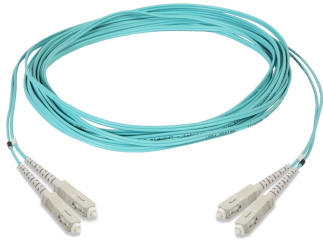

Fiber Optic Patch Cord, Duplex, OM3, SC/UPC to SC/UPC, LSZH & OFNR, aqua, 3 m

OBSOLETE

Replaced By:

2055108	Fiber Optic Patch Cord, Duplex, OM3, SC/UPC to SC/UPC, LSZH, Aqua
FFXSCSC42	OM4 SC/UPC to SC/UPC, Fiber Patch Cord, 1.6 mm Duplex, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China EMEA Europe India
Portfolio	NETCONNECT®
Product Type	Fiber patch cord, duplex

General Specifications

Connector A, quantity	2
Color, boot A	Beige
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Beige
Color, connector B	Beige
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Total Fibers, quantity	2

Dimensions

Cord Length	3 m 9.843 ft
Diameter Over Jacket	1.8 mm 0.071 in

Optical Specifications

2105091-3

Fiber Mode	Multimode
Fiber Type	OM3, LazrSPEED®
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.3 dB

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---