

Fiber Optic Patch Cord, LC to SC, OM3 XG 10 Gb/s, twin zip, 2 m, aqua

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	205

General Specifications


Connector A, quantity	2
Color, boot A	Beige
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Beige
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Total Fibers, quantity	2

Dimensions

Cord Length	2 m 6.562 ft
--------------------	----------------

Ordering Tree

2055109-2

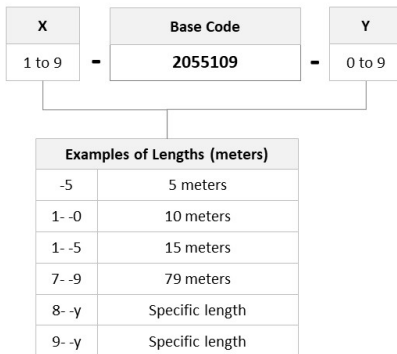

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM3, LazrSPEED®
Insertion Loss, maximum, connector A	0.15 dB
Insertion Loss, maximum, connector B	0.15 dB
Return Loss, minimum, connector A	35 dB
Return Loss, minimum, connector B	35 dB

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant

