


2055109-5

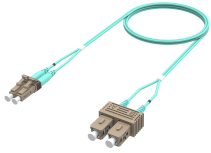

Fiber Optic Patch Cord, Duplex, Multimode, LC/UPC to SC/UPC, aqua, 5 m

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	205

General Specifications


Connector A, quantity	2
Color, boot A	Beige
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Beige
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Total Fibers, quantity	2

Dimensions

Cord Length	5 m 16.404 ft
Diameter Over Jacket	1.8 mm 0.071 in

Ordering Tree

2055109-5

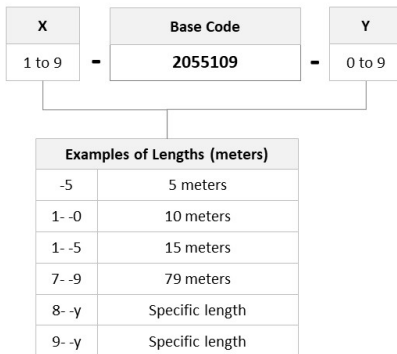

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM3, LazrSPEED®
Insertion Loss, maximum, connector A	0.15 dB
Insertion Loss, maximum, connector B	0.15 dB
Return Loss, minimum, connector A	35 dB
Return Loss, minimum, connector B	35 dB

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

