


1-2105067-5

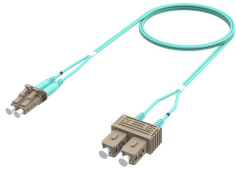

Fiber Optic Patch Cord, Duplex, Multimode, LC/UPC to SC/UPC, aqua, 15 m

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China EMEA Europe India |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, duplex |
| Product Series | 210 |

General Specifications


| | |
|-------------------------------|--------|
| Connector A, quantity | 2 |
| Color, boot A | Beige |
| Color, connector A | Beige |
| Connector B, quantity | 2 |
| Color, boot B | Beige |
| Color, connector B | Beige |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | SC/UPC |
| Jacket Color | Aqua |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|-----------------------------|-------------------|
| Cord Length | 15 m 49.213 ft |
| Diameter Over Jacket | 1.8 mm 0.071 in |

Ordering Tree

1-2105067-5

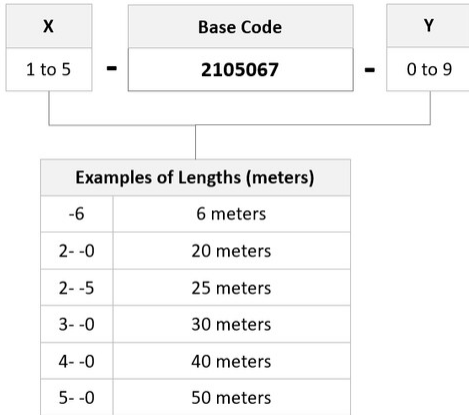

Optical Specifications

| | |
|-------------------|-----------------|
| Fiber Mode | Multimode |
| Fiber Type | OM4, LazrSPEED® |

Environmental Specifications

| | |
|----------------------------|-----------------------|
| Environmental Space | Dual Rated LSZH/Riser |
|----------------------------|-----------------------|

Packaging and Weights

| | |
|---------------------------|---|
| Packaging quantity | 1 |
|---------------------------|---|

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|-----------------------------------|
| CHINA-ROHS | Above maximum concentration value |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

