


1712214 | FPCMY-SPSC/APSC-P-5M

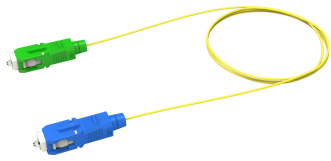

Fiber Optic Patch Cord, Simplex, Singlemode, SC/UPC to SC/APC, yellow, 5 m

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber patch cord, simplex
Product Series	FPCMY

General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	1
Color, boot B	Green
Color, connector B	Green
Interface, Connector A	SC/UPC
Interface, Connector B	SC/APC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cord Length	5 m 16.404 ft
Diameter Over Jacket	1.7 mm 0.067 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®
Insertion Loss, maximum, connector A	0.2 dB
Insertion Loss, maximum, connector B	0.35 dB
Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

Environmental Specifications

Environmental Space Plenum

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant/Exempted

