

1-2105061-5



Fiber Optic Patch Cord, Duplex, Multimode, LC/UPC to LC/UPC, LSZH & OFNR, aqua, 15 m

Product Classification

| | |
|-----------------------|--|
| Regional Availability | Asia Australia/New Zealand China India Latin America |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, duplex |
| Product Series | 210 |


General Specifications

| | |
|------------------------|--------|
| Connector A, quantity | 2 |
| Color, boot A | Aqua |
| Color, connector A | Beige |
| Connector B, quantity | 2 |
| Color, boot B | Aqua |
| Color, connector B | Beige |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | LC/UPC |
| Jacket Color | Aqua |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|----------------------|-------------------|
| Cord Length | 15 m 49.213 ft |
| Diameter Over Jacket | 1.8 mm 0.071 in |

Ordering Tree

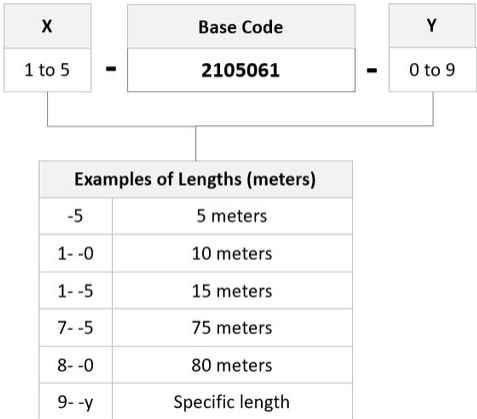

Optical Specifications

| | |
|--|-----------------|
| Fiber Mode | Multimode |
| Fiber Type | OM4, LazrSPEED® |
| Insertion Loss, maximum, connector A and B | 0.3 dB |

Environmental Specifications

| | |
|-------------------------|---|
| Environmental Space | Dual Rated LSZH/Riser |
| Qualification Standards | IEC 60332-1 IEC 60332-3 IEC 60754 IEC 61034 |

Packaging and Weights

| | |
|--------------------|---|
| Packaging quantity | 1 |
|--------------------|---|

Regulatory Compliance/Certifications

| | |
|------------|---|
| Agency | Classification |
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |



* Footnotes

1-2105061-5

Insertion Loss, maximum, connector A and B Insertion loss is measured at a room temp of +20°C (+68°F)