


Product Dimensions

Cabinet	Size (HxWxD)	Maximum Fiber Count	Access	Mounting Options	Splitter Slots	Cable Exit Location
Small (72-288)	30" x 27" x 18" (76.20 x 68.58 x 45.72 cm)	72-288 homes	all front	ground, pole	12	top or bottom
Medium (72-432)	41" x 27" x 18" (121.92 x 68.58 x 45.72 cm)	72-432 homes	all front	ground, pole	24	top or bottom
Large (72-864)	48" x 46" x 22" (121.92 x 116.84 x 55.88 cm)	72-864 homes	all front	ground	48	bottom

Recommended Jumper Lengths:

1.75 meter, 2mm RBR, for cabinet sizes 288 and 432  
2 meter, 2mm RBR, for cabinet size 864

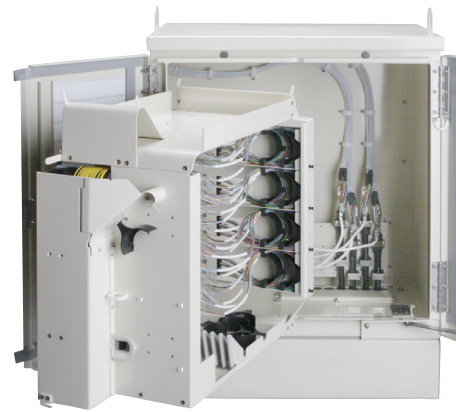

FTTX Solutions

FDH 3000 Cross-Connect

CommScope's FTTX infrastructure solutions are designed from the ground up to meet the unique requirements of FTTX networks. Designed for operational efficiency and scalability, CommScope's FTTX solutions simplify network installation, maintenance and management from the central office/head end to the outside plant.

The FDH 3000 cross-connect is designed to meet and serve the distinct needs of diverse markets and customer segments. The unique design of the FDH 3000 cross-connect provides for a rapid connection, facilitating fast service connection and reconfiguration, simplified network installations and improved installation efficiencies in the field.

Features and Benefits

Unique Design to Meet Diverse Customer Requirements  
"Craft Friendly" to support both low and high-density applications, different network system designs, and diverse installation environments

Incorporates CommScope Quality and Innovation  
CommScope is a high quality, industry-leading brand you can rely on to future-proof your network, with a complete portfolio of FTTX products and services to ensure seamless deployment and maintenance over the life of the network

Flexible and Modular

Standardized modules and accessories for all FDH 3000 cross-connect cabinets

The FDH 3000 incorporates four time-tested elements that have long impacted reliability, flexibility and operational costs within the in fiber networks:

- Bend radius protection
- Intuitive cable routing
- Easy fiber/connector access
- Physical protection

Easy to Order

Streamlined configurations simplify the ordering process

www.commscope.com

Visit our website or contact your local CommScope representative for more information.

© 2015 CommScope, Inc. All rights reserved.

All trademarks identified by ® or ™ are registered trademarks or trademarks, respectively, of CommScope, Inc. This document is for planning purposes only and is not intended to modify or supplement any specifications or warranties relating to CommScope products or services.

PS-104002-AE (12/15)

## Features and Benefits

### Three cabinet sizes

Small (72-288 fibers)  
Medium (72-432 fibers)  
Large (72-864 fibers)

### Intelligent design

Allows for standardized modules and accessories across all cabinet sizes

### Unique “swing-out frame” design

Allows for easy maintenance and access to back of modules and cables

### Features discrete ground and cable location access

Allows for locating wires without entry into the cabinets

### Integrated slack storage spools

Allows for storage of excess fiber while providing positive bend radius control

### Angled bulkhead panels

Eliminates 90° bends and assists technician with routing

### Pole mounting option

Available with small and medium termination models

### Three-point latch

Provides weather-tight seal

### Six-inch pad mount skirt

Included with all cabinets

### Hand hole options

Available in polymer-concrete


### NEMA-4 Design

Provides heavy duty protection from wind, rain and other contaminants

### Accessible with standard 216B tool

Offers flexible security options, including pad lock provisions

## FDH 3000 Cross-Connect Ordering Information

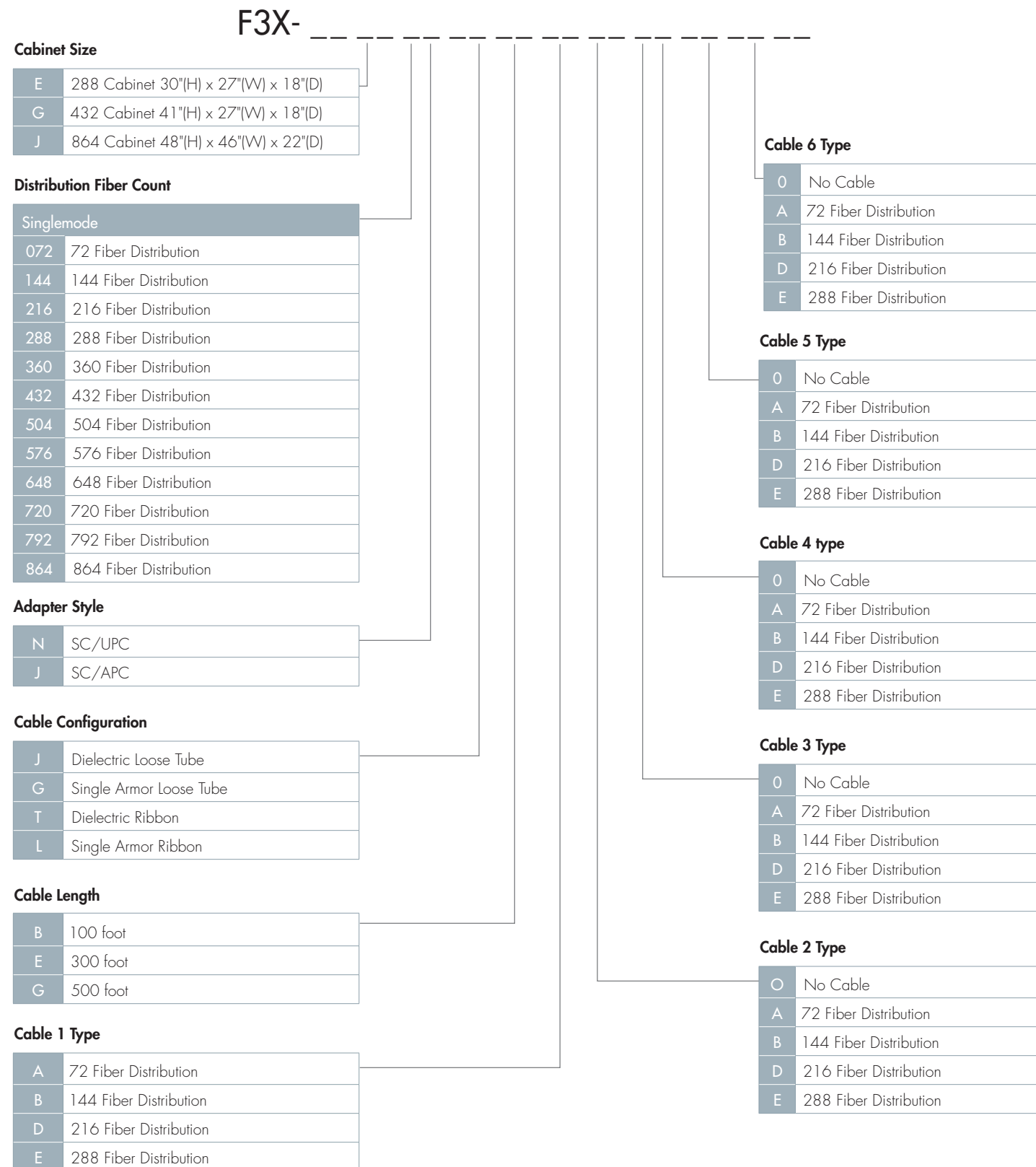

\* Distribution panels are loaded with 144 fiber groups first and 72 fiber groups last.

## Ordering Information

Description	Catalog Number		
<b>216 Tools – Can Wrench Keys</b>	Nickel plated brass can wrench key For use in loosening/tightening security screws	OSP-216BKEY1	
	Aluminum can wrench key For use in loosening/tightening security screws	OSP-216BKEY2	
	Plastic can wrench key For use in loosening/tightening security screws	OSP-216BKEY3	
<b>Cleaning Kits</b>	Alcohol cleaning kit for connector end faces	FPC-CLNKIT1	
	Almond touch up paint	ACE-ACC-PTALMD	
<b>Risers</b>	6" ground spacer/riser for small (72-288 fibers) and; medium (72-432 fibers) cabinets; Raises cabinet an additional 6"	FD3-RSRE06	
	6" ground spacer/riser for large (72-864 fibers) cabinets; Raises cabinet an additional 6"	FD3-RSRJ06	
<b>Cable Clamps</b>	Small clamp	FD3-ACCSMCIMP	
	Large clamp	FD3-ACCLGCIIMP	
	Spiral clamp	FD3-ACCMSPCLIMP	
	500 foot feeder cable for FDH 3000	FD3-ACCMPOCBL500	
	750 foot feeder cable for FDH 3000	FD3-ACCMPOCBL750	
<b>Hand Hole Kits</b>	Hand Hole and cover kit for small (72-288 fibers) and medium (72-432 fibers) cabinets	FMS-ACE100-KIT-A	
	Hand Hole and cover kit for large (72-864 fibers) cabinets	FMS-FD3J-KIT-A	
<b>Pad Mount Frames</b>	Small (72-288 fibers) and medium (72-432 fibers) pad mount frame	FD3-PMFE06	
	Large (72-864 fibers) pad mount frame	FD3-PMFJ06	
<b>Additional Panel Options</b>	Single armor loose tube 72 position APC SC	FD3MOD-072JGAB	
	Dielectric loose tube 72 position APC SC	FD3MOD-072JJAB	
	Single armor ribbon 72 position APC SC	FD3MOD-072JLAB	
	Dielectric ribbon 72 position APC SC	FD3MOD-072JTAB	
<b>Miscellaneous and Legacy Accessories</b>	Hex Key to open cabinet door Tamper resistant hex key (allen wrench), ACE cabinet	OSP-SECKEY1	
	Replacement Door Handles	Door Latch kit (latch only) FDH 3000, FONS 1, 2 and 3 cabinets	FDH-ACCHNDIKT-3
		Handle replacement PFP cabinets	FDH-ACCPFP-HNDL-1
	CSX3/CSX2 cabinet adapter bracket for PNP splitters	Standard Bracket and cables for smaller CSX2 and CSX3 cabinets	FPS-ACCCSX3RETRO
		Standard Bracket with longer feeder cable for 576 and 864 CSX3/CSX2 cabinets	FPS-ACCCSX3/2F12