


3-556148-0

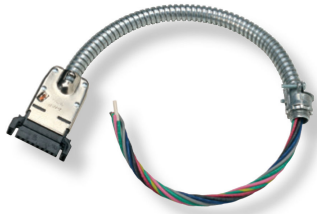

AMPINNERGY® Line Entry Cable Assembly, 8-wire/4-circuit (4-2-2), shared neutral, 30 feet

- Used to interface between manufactured wiring and other wiring systems such as building wiring, fixture wiring, or access floor workstation module wiring
- Mates to power connector cable assemblies

OBSOLETE

This product was discontinued on: June 30, 2020

Product Classification

Regional Availability	North America
Product Type	Line entry cable assembly
Product Brand	AMPINNERGY®
Product Series	AMPINNERGY

General Specifications


Application	Line entry connection
Construction Type	Corrugated hose
Interface, Connector A	Power female plug
Interface, Connector B	Unterminated
Neutral Type	Shared
Wiring	8-Wire/4 Circuit (4-2-2)

Dimensions

Cord Length	9.14 m 29.987 ft
Exposed Conductor Length	304.8 mm 12 in
Neutral Conductor Gauge, solid	10-12 AWG

Outline Drawing

3-556148-0

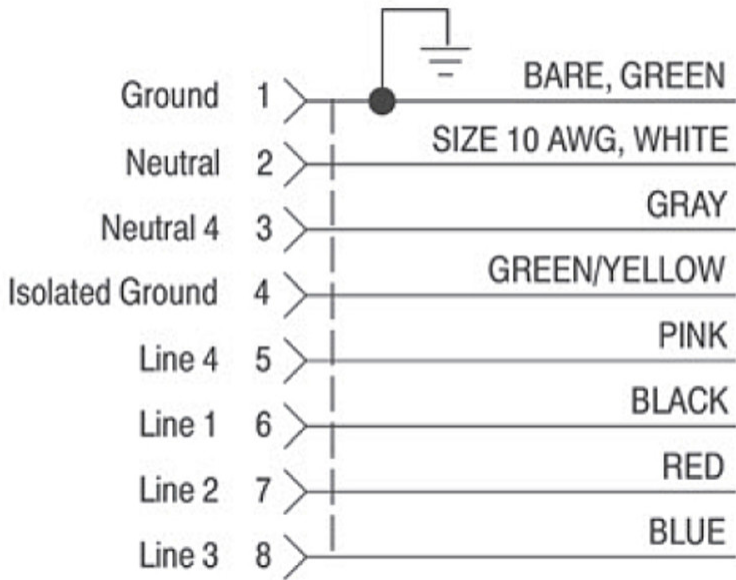

Electrical Specifications

Current Rating, maximum	20 A
Voltage Rating, maximum	125 Vac 250 Vac

Environmental Specifications

Environmental Space	Indoor
Safety Standard	CEC 2015 CSA 22.2 NEC 2013 UL 1286 UL 183 UL 498

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag