

TFBM26-3

ION®-B Series Extension Unit for WiMAX 2600



OBSOLETE

Product Classification

Product Type Extension unit

Product Brand ION®-B


General Specifications

Note Detailed Product Specifications are available. Please contact your local CommScope representative.

Power Type Medium

Dimension Drawing

TFBM26-3

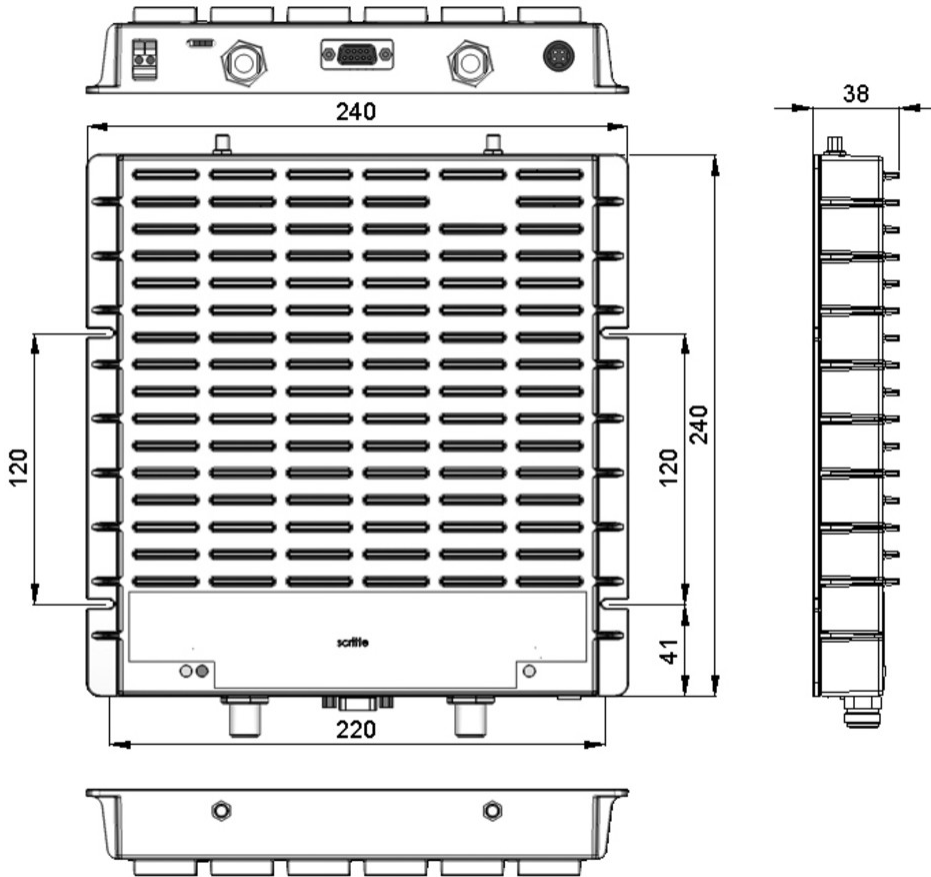

Electrical Specifications



Impedance	50 ohm
License Band	WiMAX 2600
Voltage Range	-60 to -36 Vdc

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	2496 – 2690 MHz (WiMAX 2600)
---------------------------------	------------------------------

Cabling Drawing

TFBM26-3

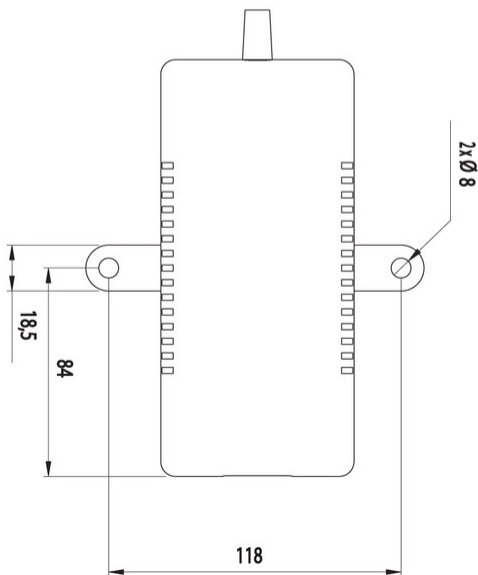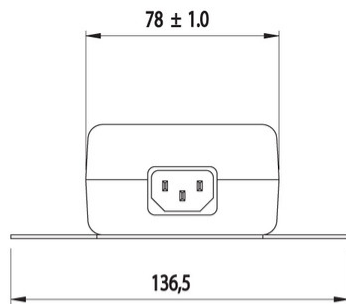

Regulatory Compliance/Certifications

Agency

ISO 9001:2015



Classification

Designed, manufactured and/or distributed under this quality management system

Included Products

TPSN3/28-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W