


# 6600D-2

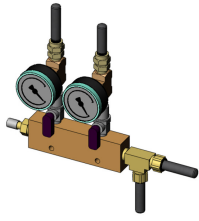

2-port Distribution Manifold, wall mountable, 0–15.0 psig, 25 ft of tubing per port

This product will be discontinued on: September 1, 2023

## Product Classification

**Product Type** Manifold

## General Specifications

**Distribution System** Manifold  
**Mounting** Wall  
**Port Count** 2  
**Port Type** 3/8 in PE tube  
**Regulated Output Pressure, maximum** 103.421 kPa | 15 psig  
**Regulated Output Pressure, minimum** 0 kPa | 0 psig

## Dimensions

**Product Height** 165.1 mm | 6.5 in  
**Product Width** 190.5 mm | 7.5 in  
**Product Depth** 63.5 mm | 2.5 in

## Environmental Specifications

**Operating Temperature** +1 °C to +40 °C (+33 °F to +104 °F)

## Packaging and Weights

**Height, packed** 406.4 mm | 16 in  
**Width, packed** 177.8 mm | 7 in  
**Depth, packed** 558.8 mm | 22 in  
**Included** 3/8 in polyethylene tubing | 90° elbow fitting | Cable tie | Male connector fitting | PTFE tape

# 6600D-2

---

**Weight, gross** 2.73 kg | 6.019 lb

**Weight, net** 1.86 kg | 4.101 lb

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

### Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

Compliant

Compliant

