

Fiber Optic Duplex Adapter, Singlemode LC/APC, green, with reduced flanges

- High quality zirconia ceramic split sleeves ensuring high precision alignment, reliability and improved reconnect ability
- Translucent easy grip dust cap and integrated mounting clips
- High quality one piece housing, no ultrasonic welding

**OBSOLETE**  
This product was discontinued on: June 1, 2022


Product Classification

Regional Availability	Asia   Australia/New Zealand   EMEA   Latin America   North America
Product Type	Fiber adapter
Product Series	OC-ADP

General Specifications

Body Style	Duplex
Color	Green
Interface	LC/APC
Mounting	Square flange
Total Ports, quantity	2
Transmission Standards	IEC 60754-1   IEC 61300-3-42

Outline Drawing

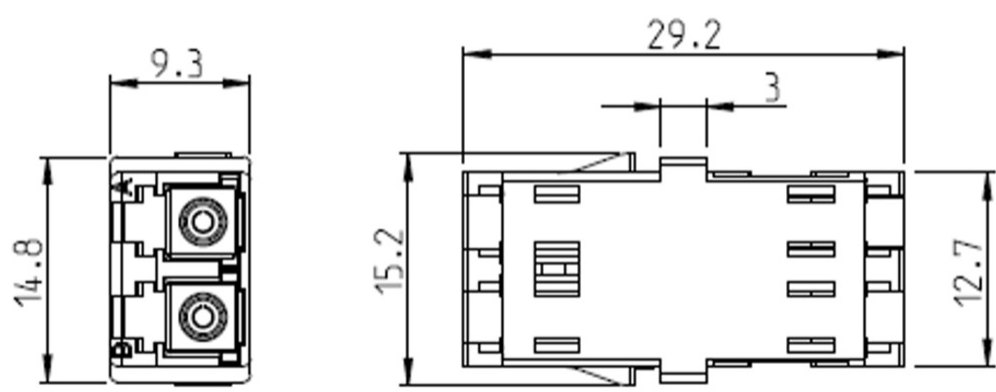

Material Specifications

**Alignment Sleeve Material** Ceramic

Mechanical Specifications

**Coupling Retention Force** 70 N | 15.737 lbf

Optical Specifications

**Fiber Mode** Singlemode

**Insertion Loss, maximum** 0.1 dB

Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

**Packaging quantity** 1

**Packaging Type** Bag

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

UK-ROHS

Compliant

