

## Pre-term Fiber Quick-Turn Program

---

The Quick-Turn Fiber program is designed to meet the needs of customers who have immediate requirements for fiber, MPO arrays and trunks. The Quick-Turn Fiber program is intended to supplement the current pre-term fiber provisioning process. This is a service provided to CommScope customers to address last minute pre-term fiber requirements, as well as fiber pre-term assemblies required to accommodate moves, adds, and changes.

### PLACE AN ORDER

- Orders are placed from distributor via [QuickturnEMEA@commscope.com](mailto:QuickturnEMEA@commscope.com)
- Maximum order quantity is 20 trunks or arrays per order.
- Targeted to ship max order quantities within 10 business days after customer submits the Quick-Turn order; lead time may vary based on availability.
- For additional quantities, please call Customer Service. Lead time subject to availability.

### PRICING

- Quick-Turn fiber orders qualify for the same project pricing discount.

### SHIPPING


- Customer pays shipping charges and duties, VAT, if applicable. Actual shipping time depends on the shipping option selected by the customer. Clear shipping instructions, including: ship to address, shipping options, and account number (FedEx, UPS. Etc.), must be included in the purchase order.



[QuickturnEMEA@commscope.com](mailto:QuickturnEMEA@commscope.com)

# Quick-Turn Product Listing

## Array assembly

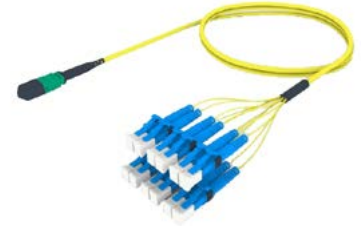

FULLY CONFIGURED MID	DESCRIPTION	BREAKOUT	LENGTH FT/MT
URGQPLCJ8-JExxxx	Ultra Low Loss SM MPO8 Unpinned to LC/UPC 8-Fiber LSZH Array Cord	24inch breakout (end B), no gland	2-999 / 1-99
URGQPLUJ8-JExxxx	Ultra Low Loss (ULL) SM, MPO8 Unpinned to LC/UPC Uniboot, 8-Fiber Array Cord, LSZH (LSZH)/Riser	24inch breakout (end B), no gland	2-999 / 1-99
URGQXLUJ8-JExxxx	Ultra Low Loss (ULL) SM, MPO8 Pinned to LC/UPC Uniboot, 8-Fiber Array Cord, LSZH (LSZH)/Riser	24inch breakout (end B), no gland	2-999 / 1-99
URGQPQJ8-JExxxx	Ultra Low Loss (ULL) SM MPO8 (Unpinned) to MPO8 (Unpinned), Fiber Extension Cable Assembly, 8-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
URGQPQXJ8-JExxxx	Ultra Low Loss (ULL) SM MPO8 (Unpinned) to MPO8 (Pinned), Fiber Extension Cable Assembly, 8-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
URGQXQXJ8-JExxxx	Ultra Low Loss (ULL) SM MPO8 (Pinned) to MPO8 (Pinned), Fiber Extension Cable Assembly, 8-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
URGMPPMGD-JAxxxx	Ultra Low Loss (ULL) SM MPO12 (Unpinned) to MPO12 (Unpinned), Fiber Extension Cable Assembly, 12-Fiber, LSZH	No breakout, no gland	2-999 / 1-99
URGMPLCGD-JExxxx	Ultra Low Loss (ULL) SM MPO12 (Unpinned) to LC/UPC, Fiber Extension Cable Assembly, 12-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
URGMXXMGD-JAxxxx	Ultra Low Loss (ULL) SM MPO12 (Pinned) to MPO12 (Pinned), Fiber Extension Cable Assembly, 12-Fiber, LSZH	No breakout, no gland	2-999 / 1-99
URGMXLCGD-JExxxx	Ultra Low Loss (ULL) SM MPO12 (Pinned) to LC/UPC, Fiber Extension Cable Assembly, 12-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
URX2C2XHF-MExxxx	Ultra Low Loss (ULL) OM4, MPO24 (Unpinned) to MPO24 (Pinned), 24-Fiber, LSZH (LSZH) Patchcord	24inch breakout (end B), no gland	2-999 / 1-99
FRWMXLCGD-JExxxx	SM MPO (Pinned) to LC/UPC, InstaPATCH® 360 Array Cord, 12-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
FRXMPLCGD-MExxxx	OM4 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Array Cord, 12-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
FRXMPMGD-MAxxxx	OM4 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Array Cord, 12-Fiber, LSZH	No breakout, no gland	2-999 / 1-99
FRXMPLCGD-MExxxx	OM4 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Array Cord, 12-Fiber, LSZH	24inch breakout (end B), no gland	2-999 / 1-99
FRXMXMGD-MAxxxx	OM4 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Array Cord, 12-Fiber, LSZH	No breakout, no gland	2-999 / 1-99
FRXMPMGD-MAxxxx	OM4 MPO (Unpinned) to MPO (Pinned), InstaPATCH® 360 Array Cord, 12-Fiber, LSZH	No breakout, no gland	2-999 / 1-99

[QuickturnEMEA@commscope.com](mailto:QuickturnEMEA@commscope.com)

# Quick-Turn Product Listing

## Trunk assembly



FULLY CONFIGURED MID	DESCRIPTION	BREAKOUT	LENGTH FT/MT
UJGMXMXCF-JBxxxx	Ultra Low Loss ULL TeraSPEED® MPO(Pinned) to MPO(Pinned) Pre-terminated Trunk Cable, MPO12, 24-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca	33-inch breakout, with gland	10-99 / 3-999
U3GMXMXCF-JBxxxx	Ultra Low Loss ULL TeraSPEED® MPO(Pinned) to MPO(Pinned) Pre-terminated Trunk Cable, MPO12, 24-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca	33-inch breakout, with gland	10-99 / 3-999
UJXMPMPCF-MBxxxx	Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to MPO(Unpinned) Pre-terminated Trunk Cable, MPO12, 24-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca	33-inch breakout, with gland	10-99 / 3-999
UJXMPMPCD-MBxxxx	Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to MPO(Unpinned) Pre-terminated Trunk Cable, MPO12, 12-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca	33-inch breakout, with gland	10-99 / 3-999
UJXMXMXCD-MBxxxx	Ultra Low Loss ULL LazrSPEED® 550 MPO(Pinned) to MPO(Pinned) Pre-terminated Trunk Cable, MPO12, 12-Fiber, LSZH, 12 fiber PmP 2.0 mm Dca	33-inch breakout, with gland	10-99 / 3-999
UJGMXMXAF-JBxxxx	Ultra Low Loss (ULL) SM MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 24-Fiber, LSZH , LSZH	33-inch breakout, with gland	10-99 / 3-999
U3GMXMXAF-JBxxx	Ultra Low Loss (ULL) SM MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 24-Fiber, LSZH	33-inch breakout, with gland	10-99 / 3-999
U3GMXMXAD-JBxxxx	Ultra Low Loss (ULL) SM MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 12-Fiber, LSZH	33-inch breakout, with gland	10-99 / 3-999
UJGMXMXAD-JBxxxx	Ultra Low Loss (ULL) SM MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 12-Fiber, LSZH	33-inch breakout, with gland	10-99 / 3-999
U3GMPMPAD-JBxxxx	Ultra Low Loss (ULL) SM MPO (Unpinned) to MPO (Unpinned) Fiber Trunk Cable Assembly, 12-Fiber, CPR Class B2ca, LSZH/Riser	33-inch breakout, with gland	10-99 / 3-999
U3VMXMXAF-NBxxxx	Ultra Low Loss (ULL) OM5 MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 24-Fiber, LSZH , LSZH	33-inch breakout, with gland	10-99 / 3-999
UJVMXMXAF-NBxxxx	Ultra Low Loss (ULL) OM5 MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 24-Fiber, LSZH , LSZH	33-inch breakout, with gland	10-99 / 3-999
U3VMXMXAD-NBxxxx	Ultra Low Loss (ULL) OM5 MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 12-Fiber, LSZH , LSZH	33-inch breakout, with gland	10-99 / 3-999
UJVMXMXAD-NBxxxx	Ultra Low Loss (ULL) OM5 MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 12-Fiber, LSZH , LSZH	33-inch breakout, with gland	10-99 / 3-999
UJXQXQXQ8-MBxxxx	Ultra Low Loss (ULL) OM4 MPO8 QSFP (Pinned) to MPO8 QSFP (Pinned), Fiber Trunk Cable Assembly, 8-Fiber, LSZH , LSZH	33-inch breakout, with gland	10-99 / 3-999

[QuickturnEMEA@commscope.com](mailto:QuickturnEMEA@commscope.com)

# Quick-Turn Product Listing

## Patch cord assembly

FULLY CONFIGURED MID	DESCRIPTION	FIBER MODE
FFWLCLC42-JXF003	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT003	Singlemode
FFWLCLC42-JXF005	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT005	Singlemode
FFWLCLC42-JXF006	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT006	Singlemode
FFWLCLC42-JXF007	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT007	Singlemode
FFWLCLC42-JXF010	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT010	Singlemode
FFWLCLC42-JXF015	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT015	Singlemode
FFWLCLC42-JXF017	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT017	Singlemode
FFWLCLC42-JXF033	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT033	Singlemode
FFWLCLC42-JXF050	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,FT050	Singlemode
FFWLCLC42-JXM002	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,MT002	Singlemode
FFWLCLC42-JXM005	JUMPER,LSZH,TS,1.6MM,DPLX,LC/LC,YL,MT005	Singlemode
FFXLCLC42-MXF003	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT003	Multimode
FFXLCLC42-MXF004	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT004	Multimode
FFXLCLC42-MXF006	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT006	Multimode
FFXLCLC42-MXF007	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT007	Multimode
FFXLCLC42-MXF008	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT008	Multimode
FFXLCLC42-MXF010	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT010	Multimode
FFXLCLC42-MXF015	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT015	Multimode
FFXLCLC42-MXF017	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT017	Multimode
FFXLCLC42-MXF020	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT020	Multimode
FFXLCLC42-MXF030	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT030	Multimode
FFXLCLC42-MXF033	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT033	Multimode
FFXLCLC42-MXF040	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT040	Multimode
FFXLCLC42-MXF050	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,FT050	Multimode
FFXLCLC42-MXM001	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,MT001	Multimode
FFXLCLC42-MXM002	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,MT002	Multimode
FFXLCLC42-MXM003	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,MT003	Multimode
FFXLCLC42-MXM005	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,MT005	Multimode
FFXLCLC42-MXM010	JUMPER,LSZH,LS,1.6MM,DPLX,LC/LC,AQ,MT010	Multimode

[QuickturnEMEA@commscope.com](mailto:QuickturnEMEA@commscope.com)

# Shipping guidelines

## SHIPPING CONDITIONS

- Customer pays shipping charges and duties, VAT, if applicable.
  - Incoterms is "FCA Commscope premises". Therefore, Commscope is not responsible for payment of freight charges, clearing goods on import (or payment of duties and VAT if applicable) as well as transport time.
  - Clear shipping instructions, including ship to address, shipping options and account number (DHL express, Fedex, TNT Etc.) must be included in the purchase order. In case of DHL Express, E-Secure authorization has to be provided by the customer prior to shipping (see point below).

## ADDITIONAL SHIPPING GUIDELINES

- Suggestion for Customer carrier request questions (EU ship from to EU destination)
  - DHL Express Small Parcel - requires carrier account (9digit #, starts with 9xxxxxxx). Clearly indicate one of following service levels: Express 12:00, Express Worldwide, Economy Select.
  - DHL Express Economy Select – on larger orders, ask upfront if customer has a weight limit or limit of quantity of cartons before requiring palletization. Requires carrier account (9digit #, starts with 9xxxxxxx). Recommended for shipments up to 70 kgs.
  - E-Secure DHL Express - Please note that the first time Commscope uses your account number, you need to provide authorization for the use with DHL Express through E-secure (via MyDHL+). Please add the below email addresses yourself through E-secure or approve the use immediately (upon receipt of the email you will receive from E-secure). Without this authorization, Commscope cannot use your account number and ship.  
Materials to be shipped to Non-EU countries: [kevin.eastham@commscope.com](mailto:kevin.eastham@commscope.com)  
Materials to be shipped to EU countries: [petr.maler@commscope.com](mailto:petr.maler@commscope.com)
  - TNT Economy Service – recommended for larger orders over 70 kgs. Requires carrier account (5 or 6 digit #).
  - If shipment requires air freight service, please use DHL Express Small Parcel or case of pallets please ask for tailor made solution with your preferred carrier.

MOST FREQUENT PRODUCT PACKAGING					
	Length	Width	Height	Weight	Recommended carrier
Box	50 cm	50 cm	27 cm	3 - 7kg	DHL Express Economy Select
Pallet	80 cm	60 cm	40 - 90 cm	25 - 70 kg	DHL Express Economy Select
Pallet	120 cm	80 cm	60 - 120 cm	40 - 70 kg	DHL Express Economy Select
Pallet	120 cm	80 cm	60 - 120 cm	70 - 200 kg	TNT Economy Service

The guide on length limits will keep the size of packaging required to hold product within a small parcel transportation category. If customer order various lengths, customer may receive multiple small cartons. Packaging is based upon vendor capability.

CommScope pushes the boundaries of communications technology with game-changing ideas and ground-breaking discoveries that spark profound human achievement.

We collaborate with our customers and partners to design, create and build the world's most advanced networks. It is our passion and commitment to identify the next opportunity and realize a better tomorrow. Discover more at [commscope.com](https://commscope.com).

---

[commscope.com](https://commscope.com)

Visit our website or contact your local CommScope representative for more information.

© 2022 CommScope, Inc. All rights reserved.

All trademarks identified by ™ or ® are trademarks or registered trademarks in the US and may be registered in other countries. All product names, trademarks and registered trademarks are property of their respective owners. This document is for planning purposes only and is not intended to modify or supplement any specifications or warranties relating to CommScope products or services.