


FE-12104-T-R4

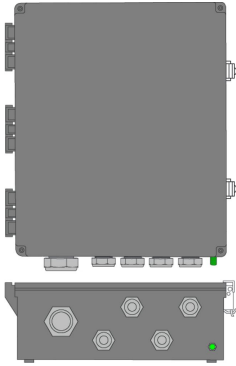

HELIAX® Fiber and Power Junction Box for 1 Hybrid Trunk / 4 Hybrid Jumper Cables, Blue and Grey Terminal Blocks

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Outdoor junction box
Product Brand	HELIAX®

General Specifications

Application	Used as a fiber/power junction box
Cable Entry, quantity, maximum, bottom	5
Color	Gray
Mounting	Pipe, 44–114 mm (1.75–4.5 in) OD Wall

Dimensions

Height	317.5 mm 12.5 in
Width	266.7 mm 10.5 in
Depth	101.6 mm 4 in
Cable Entry Fiber Gland Size, maximum	25 mm 0.984 in
Cable Entry Fiber Gland Size, minimum	18 mm 0.709 in
Cable Entry Jumper Gland Size, maximum	18 mm 0.709 in
Cable Entry Jumper Gland Size, minimum	13 mm 0.512 in

Material Specifications

Material Type	High-impact polycarbonate, UV resistant
----------------------	---

Environmental Specifications

FE-12104-T-R4

Operating Temperature	-40 °C to +75 °C (-40 °F to +167 °F)
Environmental Space	Indoor Outdoor
Qualification Standards	IEC 60529:2001, IP67

Packaging and Weights

Included	Mounting kit
Weight, net	1.579 kg 3.48 lb

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

