


FGS-MEXP-LP-A/B/F

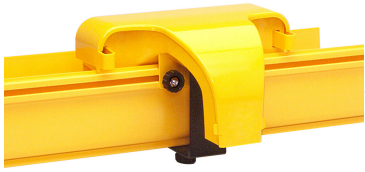

FiberGuide® 2-Inch Low profile Express Exit™, 4x4in, 4x6in, 4x12in, 4x24in, Yellow

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Express exit |
| Product Brand | FiberGuide® |
| Product Series | FGS |

General Specifications

| | |
|---------------------|--------------|
| Color | Yellow |
| Orientation | Horizontal |
| Section Type | Express exit |

Dimensions

| | |
|--------------------------|---|
| Height | 132 mm 5.197 in |
| Width | 260 mm 10.236 in |
| System Dimensions | 102 mm x 102 mm (4 in x 4 in) 102 mm x 152 mm (4 in x 6 in) 102 mm x 305 mm (4 in x 12 in) 102 mm x 610 mm (4 in x 24 in) |

Ordering Tree

FGS-MEXP-LP-A/B/F

FGS ⁹ B - MEXP - ¹⁰ A/B/F

Section Color

| | | |
|---|-------|--------|
| 9 | empty | yellow |
| | B | black |

Section Size

| | | |
|----|-----------|--|
| 10 | A/B/F | 4 x 4/6/12 in, with 2 x 2 in exit |
| | E-A/B/F | 4 x 4/6/12 in, with 4 x 4 in exit |
| | F-F/H-NC | 4 x 12/18/24 in, with 4 x 12 in exit, no cover |
| | G-A/B/F | 4 x 4/6/12 in, with 4 x 6 in exit |
| | LP-A/B/F | 4 x 4/6/12 in, with 2 x 2 in exit, low profile |
| | LP-CA | 4 x 4/6/12 in, with 2 x 4 in exit, low profile |
| | LP-G | 2 x 6 in, with 2 x 2 in exit, low profile |
| | GS-ABF-NC | 4 x 4/6/12 in, with 4 x 6 in exit, no cover |
| | CV | cover |
| | NC | no cover |

Material Specifications

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Weight, net 0.98 kg | 2.161 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant

