


FCM-67/OGT092-A

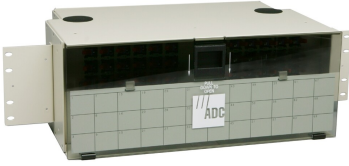

FDF Fiber Termination Panel, 144 SC/UPC, singlemode, 7 in x 19 in, putty white, pre-terminated with OSP cable, 92 meters, stub tail at far end

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with OSP cable
Product Series	FDF

General Specifications

Functionality	Patching
Application	Used in rear-load FDF-style frames only
Body Style	Symmetrical
Cable Exit Location	Upward
Cable Stub Type	OSP, ribbon
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Interface, rear	Stub tail
Patch Cord Entry Location	Front, left side Front, right side
Rack Type	EIA 23 in
Rack Units	4
Shelf Movement	Fixed
Total Ports, quantity	144

Dimensions

Height	177.8 mm 7 in
Width	482.6 mm 19 in
Depth	304.8 mm 12 in

FCM-67/OGT092-A

Cable Length 92 m | 301.837 ft

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

Packaging quantity 1