

FPX-3FS7/07HU153



FPX Fiber Optic Termination Panel with Indoor/Outdoor Cable, 3RU, 19in, Singlemode, 72 fiber, SC/UPC connectors, Stub tail at far end, putty white, 153m

Product Classification

| | |
|-----------------------|-----------------------------------|
| Regional Availability | Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber patch panel, with IFC cable |
| Product Series | FPX |

General Specifications


| | |
|----------------------------------|-----------------------|
| Functionality | Patching |
| Adapter Packs Included, quantity | 6 |
| Body Style | Symmetrical |
| Cable Exit Location | Upward |
| Cable Stub Type | IFC |
| Color | Putty white |
| Growth Configuration | Fully loaded |
| Interface, front | SC/UPC |
| Interface, rear | Stub tail |
| Rack Type | EIA 19 in EIA 23 in |
| Rack Units | 3 |
| Shelf Movement | Sliding |
| Total Fibers, quantity | 72 |
| Total Ports, quantity | 72 |

Dimensions

| | |
|--------------|---------------------|
| Height | 133.35 mm 5.25 in |
| Width | 482.6 mm 19 in |
| Depth | 304.8 mm 12 in |
| Cable Length | 153 m 501.969 ft |

FPX-3FS7/07HU153

Ordering Tree

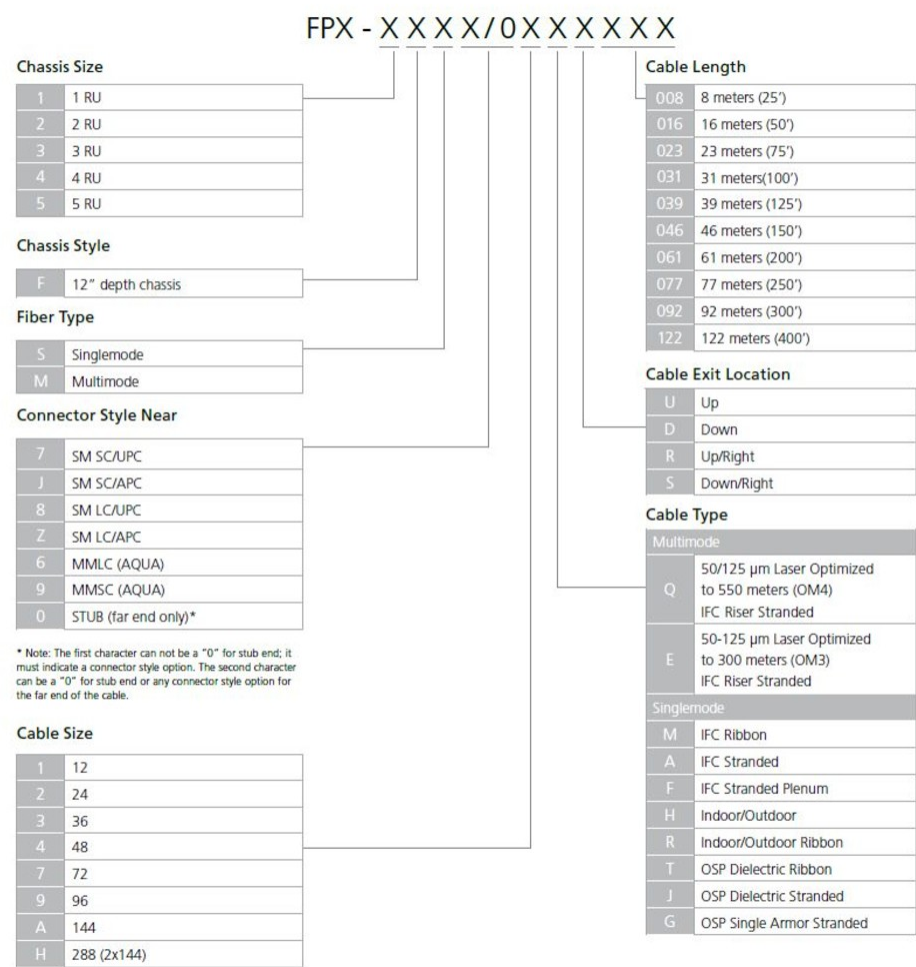

Material Specifications

| | |
|---------------|---------------|
| Finish | Powder coated |
| Material Type | Steel |

Optical Specifications

| | |
|------------|------------|
| Fiber Mode | Singlemode |
|------------|------------|

Environmental Specifications

| | |
|-----------------------|--------------------------------------|
| Operating Temperature | -40 °C to +85 °C (-40 °F to +185 °F) |
| Storage Temperature | -40 °C to +85 °C (-40 °F to +185 °F) |

FPX-3FS7/07HU153

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|--|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |

