

FPXB-1FS7/02HU305



FPX Fiber Optic Termination Panel with Indoor/Outdoor Cable, 1RU, 19in, Singlemode, 24 fiber, SC/UPC connectors, Stub tail at far end, black, 305m

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with indoor/outdoor cable
Product Series	FPX

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	2
Body Style	Symmetrical
Cable Exit Location	Upward
Cable Stub Type	Indoor/Outdoor
Color	Black
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Interface, rear	Stub tail
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Fibers, quantity	24
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	304.8 mm 12 in
Cable Length	305 m 1,000.656 ft

FPXB-1FS7/02HU305

Ordering Tree

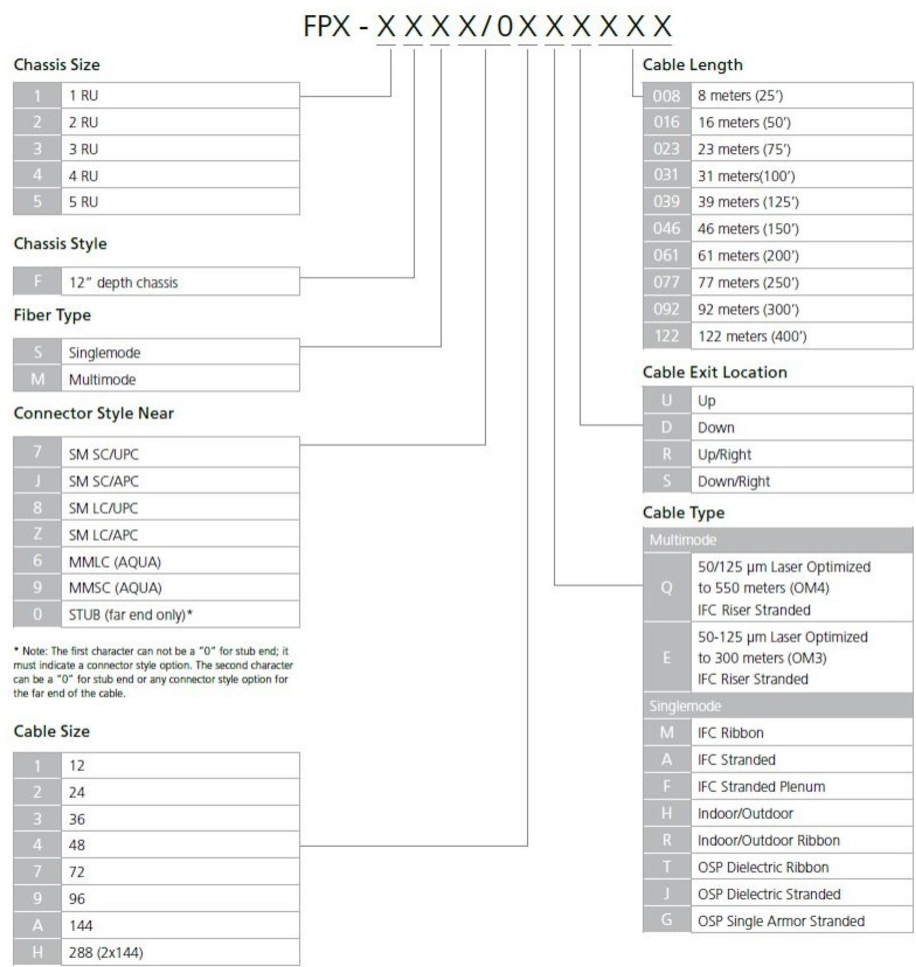

* Note: The first character can not be a "0" for stub end; it must indicate a connector style option. The second character can be a "0" for stub end or any connector style option for the far end of the cable.

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +85 °C (-40 °F to +185 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

FPXB-1FS7/02HU305

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

