


FPC2-APSC/PLC-1M

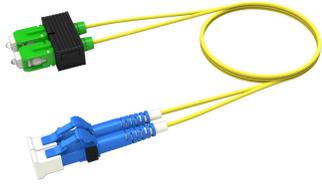

Fiber Optic Patch Cord, Duplex, Singlemode, SC/APC to LC/UPC, yellow, 1 m

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber patch cord, duplex
Product Series	FPC2

General Specifications

Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	2
Color, boot B	Green
Color, connector B	Green
Interface, Connector A	LC/UPC
Interface, Connector B	SC/APC
Jacket Color	Yellow
Total Fibers, quantity	2

Dimensions

Cord Length	1 m 3.281 ft
Diameter Over Jacket	2 mm 0.079 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS1
Insertion Loss, maximum, connector A	0.3 dB

FPC2-APSC/PLC-1M

Insertion Loss, maximum, connector B	0.35 dB
Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

Environmental Specifications

Environmental Space	Riser
----------------------------	-------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

