

TFAM91/21-14

ION®-B Series Medium Power Remote Unit for EGSM 900 and UMTS



OBSOLETE

Product Classification


 
Product Type	Remote unit
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
Power Class	Medium

Dimension Drawing

TFAM91/21-14

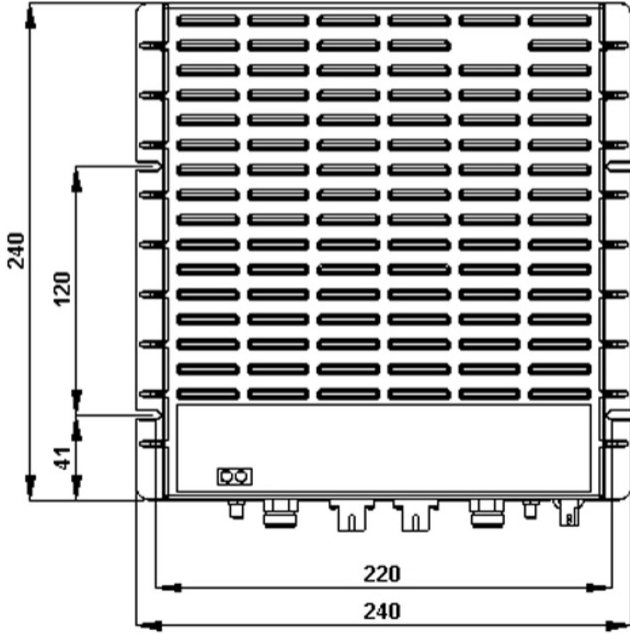

Electrical Specifications

Impedance 50 ohm

License Band EGSM 900 | UMTS

Voltage Range 85 to 265 Vac

Electrical Specifications, Rx (Uplink)

Operating Frequency Band 1920 – 1980 MHz (UMTS) | 880 – 915 MHz (EGSM 900)

Electrical Specifications, Tx (Downlink)

Operating Frequency Band 2110 – 2170 MHz (UMTS) | 925 – 960 MHz (CEL 900)

Regulatory Compliance/Certifications

TFAM91/21-14

Agency**Classification**

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted



Included Products

TPSN1/05-40 – Power Supply Adapter ION®-B Series Remote Units, 40 W

TPSN1/05-40

Power Supply Adapter ION®-B Series Remote Units, 40 W



Product Classification

Product Type Power adapters


Product Brand ION®-B

General Specifications

Note Detailed Product Specifications are available. Please contact your local CommScope representative.

Dimension Drawing

TPSN1/05-40

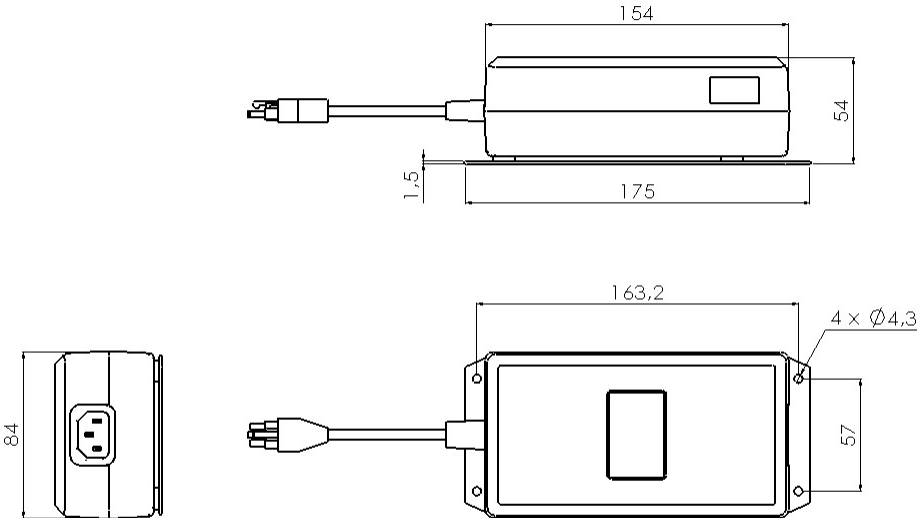

Electrical Specifications

Output Power, maximum 40 W

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system