

TFAM91/21-14

ION®-B Series Medium Power Remote Unit for EGSM 900 and UMTS



OBSOLETE

Product Classification


 
Product Type	Remote unit
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
Power Class	Medium

Dimension Drawing

TFAM91/21-14

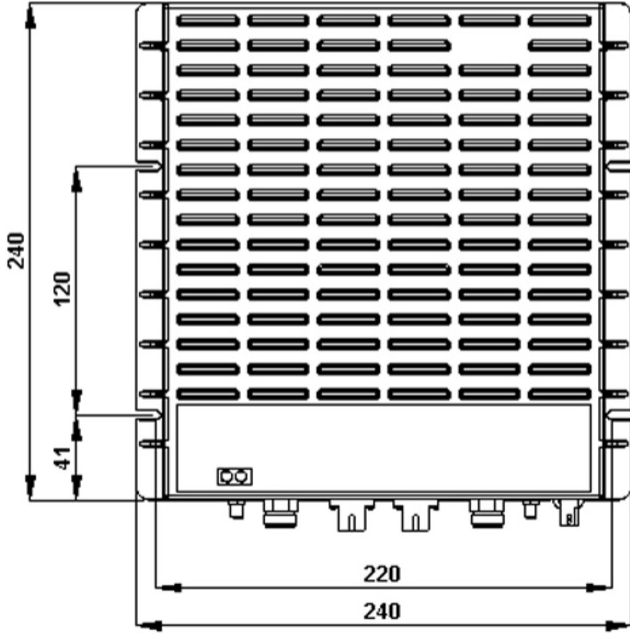

Electrical Specifications

Impedance	50 ohm
License Band	EGSM 900 UMTS
Voltage Range	85 to 265 Vac

Electrical Specifications, Rx (Uplink)

Operating Frequency Band	1920 – 1980 MHz (UMTS) 880 – 915 MHz (EGSM 900)
---------------------------------	---

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	2110 – 2170 MHz (UMTS) 925 – 960 MHz (CEL 900)
---------------------------------	--

Regulatory Compliance/Certifications

TFAM91/21-14

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- TPSN1/05-40 – Power Supply Adapter ION®-B Series Remote Units, 40 W