



HELIAX® standard product selection guide 2017

Second Edition

HELIAX® Standard product selection guide 2017

Index

SureFlex Cable Assemblies; Superflexible 1/2-Inch Cable	2
D-CLASS SureFlex Cable Assemblies; Superflexible 1/2-Inch Cable	4
SureFlex Cable Assemblies; Standard 1/2-Inch Cable.....	6
D-CLASS SureFlex Cable Assemblies; Standard 1/2-Inch Cable	8
SureFlex Cable Assemblies; Superflexible 1/4-Inch Cable	11
SureFlex Cable Assemblies; Superflexible 3/8-Inch Cable	13
Plenum Case Assemblies.....	15
50 Ohm Connectors	17
Tools	21
Replacement Blade Kits	23
Protective Cap Kits.....	23
Surge Arrestors.....	23
Grounding Kits	24
Hangers	25
Installation Accessories and Tools	26
Helix® RF—Coaxial Cable	27
LDF4-50A	29
FSJ4-50B.....	30
AVA5-50	31
AVA6-50	32
AVA7-50	33
Fire Retardant Cable Products Portfolio	34
Helix® Small Cell Corrugated Cable Products Portfolio	35
4.3-10 Cable Products Portfolio	36
Helix® Wireless Connector Video Links	37
CommScope E-catalog	39

Reference Key

Connector type	Description
DM	DIN Male
DF	DIN Female
NM	N Type Male
NF	N Type Female
DR	DIN Right Angle Male
HM	4.3-10 Male
HF	4.3-10 Female
NR	Right Angle Male
BHC	Bulk Head Connector
HMP	4.3-10 Male push/pull
HR	Right Angle 4.3-10
KM	4.1.–9.5 DIN straight male

HELIAX® RF Jumpers

Model Number Nomenclature Chart

¹F4 - ²* ³HMDM - ⁴3M - ⁵** - ⁶***

Cable Type

1	F4, F4A	FSJ4-50B SUPERFLEX ½"
	L4, L4A	LDF4-50A STANDARD FLEX ½"
	F4R, F4RNA	FIRE RETARDANT FSJ4
	L4R, L4RNA	FIRE RETARDANT LDF4
	HL	PLENUM (COPPER)

Wildcard A: P or HP

2	P	Plated (old nomenclature used on standard jumpers)
	HP	HELIAX® Performance

Wild Card A: Examples

3	HM	4.3-10 STRAIGHT MALE
	HR	4.3-10 RIGHT ANGLE MALE
	DM	7-16 DIN STRAIGHT MALE
	DR	7-16 DIN RIGHT ANGLE MALE
	KM	4.1-9.5 DIN STRAIGHT MALE
	HF	4.3-10 STRAIGHT FEMALE
	DF	7-16 DIN STRAIGHT FEMALE

Length (M/Ft): Examples

4	3M	3 Meters
	3M5	3.5 Meters
	3	3 Feet

Wildcard B

5	-D	D-CLASS
	-P	PREMIUM
	-PB	PREMIUM BIRDPROOF
	-SGW	SUREGUARD
	-SGB	SUREGUARD BIRDPROOF
	-X	PIGTAIL (1-END FIT)

Wildcard C

Only use when jumper is a D-Class variant with other features. -D is always last in the nomenclature.

6	-D	D-CLASS
---	----	---------

Example: F4-HM³HM-3M-SGW-D
SGW feature on a D-CLASS jumper

SureFlex® cable and connectors are physically bonded to create an assembly that delivers outstanding RF results where they matter most: passive intermodulation (PIM), voltage standing wave ratio (VSWR), and distance-to-fault (DTF). CommScope tests each assembly for PIM, VSWR and DTF—sharing the results on WebTrak®.

SureFlex® cable assemblies meet IP68 standards

SureFlex Cable Assemblies; Superflexible 1/2-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With superflexible 1/2-Inch FSJ4-50B cable				
7-16 DIN Male to 7-16 DIN Male	2'	F4-DMDM-2-D	.5M	F4-DMDM-M5-D
	3'	F4-DMDM-3-D	1M	F4-DMDM-1M-D
	4'	F4-DMDM-4-D	1.5M	F4-DMDM-1M5-D
	6'	F4-DMDM-6-D	2M	F4-DMDM-2M-D
	8'	F4-DMDM-8-D	2.5M	F4-DMDM-2M5-D
	10'	F4-DMDM-10-D	3M	F4-DMDM-3M-D
	12'	F4-DMDM-12-D	4M	F4-DMDM-4M-D
	15'	F4-DMDM-15-D	5M	F4-DMDM-5M-D
	20'	F4-DMDM-20-D	6M	F4-DMDM-6M-D
	30'	F4-DMDM-30-D	10M	F4-DMDM-10M-D
7-16 DIN Male to 7-16 DIN Male Right Angle	10'	F4-DMDR-10-D	3M	F4-DMDR-3M-D
	15'	F4-DMDR-15-D	5M	F4-DMDR-5M-D
	20'	F4-DMDR-20-D	6M	F4-DMDR-6M-D
	25'	F4-DMDR-25-D	8M	F4-DMDR-8M-D
	30'	F4-DMDR-30-D	10M	F4-DMDR-10M-D

continued



SureFlex Cable Assemblies; Superflexible 1/2-Inch Cable *continued*

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With superflexible 1/2-Inch FSJ4-50B cable				
7-16 DIN Male to 7-16 DIN Male	2'	F4A-DMDM-2-P	.5M	F4A-DMDM-M5-P
	3'	F4A-DMDM-3-P	1M	F4A-DMDM-1M-P
	4'	F4A-DMDM-4-P	1.5M	F4A-DMDM-1M5-P
	6'	F4A-DMDM-6-P	2M	F4A-DMDM-2M-P
	8'	F4A-DMDM-8-P	2.5M	F4A-DMDM-2M5-P
	10'	F4A-DMDM-10-P	3M	F4A-DMDM-3M-P
	12'	F4A-DMDM-12-P	3.5M	F4A-DMDM-3M5-P
	15'	F4A-DMDM-15-P	4M	F4A-DMDM-4M-P
	20'	F4A-DMDM-20-P	6M	F4A-DMDM-6M-P
	30'	F4A-DMDM-30-P	10M	F4A-DMDM-10M-P
7-16 DIN Male to 7-16 DIN Male Right Angle	10'	F4A-DMDR-10-P	3M	F4A-DMDR-3M-P
	15'	F4A-DMDR-15-P	5M	F4A-DMDR-5M-P
	20'	F4A-DMDR-20-P	6M	F4A-DMDR-6M-P
	25'	F4A-DMDR-25-P	8M	F4A-DMDR-8M-P
	30'	F4A-DMDR-30-P	10M	F4A-DMDR-10M-P

D-CLASS SureFlex Cable Assemblies; Superflexible 1/2-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
D-CLASS SureFlex Cable Assemblies With superflexible 1/2-Inch FSJ4-50B cable				
4.3-10 Male to 7-16 DIN Male	2'	F4-HMDM-2-D	.5M	F4-HMHM-M5-D
	3'	F4-HMDM-3-D	1M	F4-HMDM-1M-D
	4'	F4-HMDM-4-D	1.5M	F4-HMDM-1M5-D
	6'	F4-HMDM-6-D	2M	F4-HMDM-2M-D
	8'	F4-HMDM-8-D	2.5M	F4-HMDM-2M5-D
	10'	F4-HMDM-10-D	3M	F4-HMDM-3M-D
	12'	F4-HMDM-12-D	4M	F4-HMDM-4M-D
	15'	F4-HMDM-15-D	5M	F4-HMDM-5M-D
	20'	F4-HMDM-20-D	6M	F4-HMDM-6M-D
	25'	F4-HMDM-25-D	8M	F4-HMDM-8M-D
	30'	F4-HMDM-30-D	10M	F4-HMDM-10M-D
4.3-10 Male Right Angle to 7-16 DIN Male	10'	F4-HRDM-10-D	3M	F4-HRDM-3M-D
	15'	F4-HRDM-15-D	5M	F4-HRDM-5M-D
	20'	F4-HRDM-20-D	6M	F4-HRDM-6M-D
	25'	F4-HRDM-25-D	8M	F4-HRDM-8M-D
	30'	F4-HRDM-30-D	10M	F4-HRDM-10M-D
4.3-10 Male to 7-16 DIN Male Right Angle	10'	F4-HMDR-10-D	3M	F4-HMDR-3M-D
	15'	F4-HMDR-15-D	5M	F4-HMDR-5M-D
	20'	F4-HMDR-20-D	6M	F4-HMDR-6M-D
	25'	F4-HMDR-25-D	8M	F4-HMDR-8M-D
	30'	F4-HMDR-30-D	10M	F4-HMDR-10M-D

continued



D-CLASS SureFlex Cable Assemblies; Superflexible 1/2-Inch Cable

continued

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
D-CLASS SureFlex Cable Assemblies With superflexible 1/2-Inch FSJ4-50B cable				
4.3-10 Male to 4.3-10 Male	2'	F4-HMHH-2-D	.5M	F4-HMHH-M5-D
	3'	F4-HMHH-3-D	1M	F4-HMHH-1M-D
	4'	F4-HMHH-4-D	1.5M	F4-HMHH-1M5-D
	6'	F4-HMHH-6-D	2M	F4-HMHH-2M-D
	8'	F4-HMHH-8-D	2.5M	F4-HMHH-2M5-D
	10'	F4-HMHH-10-D	3M	F4-HMHH-3M-D
	12'	F4-HMHH-12-D	4M	F4-HMHH-4M-D
	15'	F4-HMHH-15-D	5M	F4-HMHH-5M-D
	20'	F4-HMHH-20-D	6M	F4-HMHH-6M-D
	25'	F4-HMHH-25-D	8M	F4-HMHH-8M-D
	30'	F4-HMHH-30-D	10M	F4-HMHH-10M-D
4.3-10 Male Right Angle to 4.3-10 Male Right Angle	10'	F4-HRHH-10-D	3M	F4-HMDR-3M-D
	15'	F4-HRHH-15-D	5M	F4-HMDR-5M-D
	20'	F4-HRHH-20-D	6M	F4-HMDR-6M-D
	25'	F4-HRHH-25-D	8M	F4-HMDR-8M-D
	30'	F4-HRHH-30-D	10M	F4-HMDR-10M-D



SureFlex Cable Assemblies; Standard 1/2-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With standard 1/2-Inch LDF4-50A cable				
7-16 DIN Male to 7-16 DIN Male	3'	L4A-DMDM-3-P	1M	L4A-DMDM-1M-P
	4'	L4A-DMDM-4-P	1.5M	L4A-DMDM-1M5-P
	6'	L4A-DMDM-6-P	2M	L4A-DMDM-2M-P
	8'	L4A-DMDM-8-P	2.5M	L4A-DMDM-2M5-P
	10'	L4A-DMDM-10-P	3M	L4A-DMDM-3M-P
	12'	L4A-DMDM-12-P	4M	L4A-DMDM-4M-P
	15'	L4A-DMDM-15-P	5M	L4A-DMDM-5M-P
	20'	L4A-DMDM-20-P	6M	L4A-DMDM-6M-P
	30'	L4A-DMDM-30-P	10M	L4A-DMDM-10M-P
	40'	L4A-DMDM-40-P	12M	L4A-DMDM-12M-P
	60'	L4A-DMDM-60-P	18M	L4A-DMDM-18M-P
7-16 DIN Male to 7-16 DIN Male Right Angle	6'	L4A-DMDR-6-P	2M	L4A-DMDR-2M-P
	8'	L4A-DMDR-8-P	2.5M	L4A-DMDR-2M5-P
	10'	L4A-DMDR-10-P	3M	L4A-DMDR-3M-P
	15'	L4A-DMDR-15-P	5M	L4A-DMDR-5M-P
	20'	L4A-DMDR-20-P	6M	L4A-DMDR-6M-P

continued

SureFlex Cable Assemblies; Standard 1/2-Inch Cable *continued*

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With standard 1/2-Inch LDF4-50A cable and SureGuard®weatherproofing				
7-16 DIN Male to 7-16 DIN Male	3'	L4A-DMDM-3-P-SGW	1M	L4A-DMDM-1M-P-SGW
	4'	L4A-DMDM-4-P-SGW	1.5M	L4A-DMDM-1M5-P-SGW
	6'	L4A-DMDM-6-P-SGW	2M	L4A-DMDM-2M-P-SGW
	8'	L4A-DMDM-8-P-SGW	2.5M	L4A-DMDM-2M5-P-SGW
	10'	L4A-DMDM-10-P-SGW	3M	L4A-DMDM-3M-P-SGW
	12'	L4A-DMDM-12-P-SGW	3.5M	L4A-DMDM-3M5-P-SGW
	15'	L4A-DMDM-15-P-SGW	5M	L4A-DMDM-5M-P-SGW
	20'	L4A-DMDM-20-P-SGW	6M	L4A-DMDM-6M-P-SGW
7-16 DIN Male to 7-16 DIN Male Right Angle	6'	L4A-DMDR-6-P-SGW	2M	L4A-DMDR-2M-P-SGW
	8'	L4A-DMDR-8-P-SGW	2.5M	L4A-DMDR-2M5-P-SGW
	10'	L4A-DMDR-10-P-SGW	3M	L4A-DMDR-3M-P-SGW
	15'	L4A-DMDR-15-P-SGW	5M	L4A-DMDR-5M-P-SGW
	20'	L4A-DMDR-20-P-SGW	6M	L4A-DMDR-6M-P-SGW

D-CLASS SureFlex Cable Assemblies; Standard 1/2-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
D-CLASS SureFlex Cable Assemblies With standard 1/2-Inch LDF4-50A cable				
4.3-10 Male to 7-16 DIN Male	3'	L4-HMDM-3-D	1M	L4-HMDM-1M-D
	4'	L4-HMDM-4-D	1.5M	L4-HMDM-1M5-D
	6'	L4-HMDM-6-D	2M	L4-HMDM-2M-D
	8'	L4-HMDM-8-D	2.5M	L4-HMDM-2M5-D
	10'	L4-HMDM-10-D	3M	L4-HMDM-3M-D
	12'	L4-HMDM-12-D	4M	L4-HMDM-4M-D
	15'	L4-HMDM-15-D	5M	L4-HMDM-5M-D
	20'	L4-HMDM-20-D	6M	L4-HMDM-6M-D
	25'	L4-HMDM-25-D	8M	L4-HMDM-8M-D
	30'	L4-HMDM-30-D	10M	L4-HMDM-10M-D
4.3-10 Male to 7-16 DIN Male Right Angle	6'	L4-HMDR-6-D	2M	L4-HMDR-2M-D
	8'	L4-HMDR-8-D	2.5M	L4-HMDR-2M5-D
	10'	L4-HMDR-10-D	3M	L4-HMDR-3M-D
	15'	L4-HMDR-15-D	5M	L4-HMDR-5M-D
	20'	L4-HMDR-20-D	6M	L4-HMDR-6M-D
4.3-10 Male Right Angle to 7-16 DIN Male	6'	L4-HRDM-6-D	2M	L4-HRDM-2M-D
	8'	L4-HRDM-8-D	2.5M	L4-HRDM-2M5-D
	10'	L4-HRDM-10-D	3M	L4-HRDM-3M-D
	15'	L4-HRDM-15-D	5M	L4-HRDM-5M-D
	20'	L4-HRDM-20-D	6M	L4-HRDM-6M-D

continued



D-CLASS SureFlex Cable Assemblies; Standard 1/2-Inch Cable *continued*

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
D-CLASS SureFlex Cable Assemblies With standard 1/2-Inch LDF4-50A cable				
4.3-10 Male to 4.3-10 Male	3'	L4-HMHM-3-D	1M	L4-HMHM-1M-D
	4'	L4-HMHM-4-D	1.5M	L4-HMHM-1M5-D
	6'	L4-HMHM-6-D	2M	L4-HMHM-2M-D
	8'	L4-HMHM-8-D	2.5M	L4-HMHM-2M5-D
	10'	L4-HMHM-10-D	3M	L4-HMHM-3M-D
	12'	L4-HMHM-12-D	4M	L4-HMHM-4M-D
	15'	L4-HMHM-15-D	5M	L4-HMHM-5M-D
	20'	L4-HMHM-20-D	6M	L4-HMHM-6M-D
	25'	L4-HMHM-25-D	8M	L4-HMHM-8M-D
	30'	L4-HMHM-30-D	10M	L4-HMHM-10M-D



D-CLASS SureFlex Cable Assemblies; Standard 1/2-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
D-CLASS SureFlex Cable Assemblies with standard 1/2-Inch LDF4-50A cable and SureGuard weatherproofing				
4.3-10 Male to 7-16 DIN Male	3'	L4-HMDM-3-SGW-D	1M	L4-HMDM-1M-SGW-D
	4'	L4-HMDM-4-SGW-D	1.5M	L4-HMDM-1M5-SGW-D
	6'	L4-HMDM-6-SGW-D	2M	L4-HMDM-2M-SGW-D
	8'	L4-HMDM-8-SGW-D	2.5M	L4-HMDM-2M5-SGW-D
	10'	L4-HMDM-10-SGW-D	3M	L4-HMDM-3M-SGW-D
	12'	L4-HMDM-12-SGW-D	4M	L4-HMDM-4M-SGW-D
	15'	L4-HMDM-15-SGW-D	5M	L4-HMDM-5M-SGW-D
	20'	L4-HMDM-20-SGW-D	6M	L4-HMDM-6M-SGW-D
	25'	L4-HMDM-25-SGW-D	8M	L4-HMDM-8M-SGW-D
	30'	L4-HMDM-30-SGW-D	10M	L4-HMDM-10M-SGW-D
4.3-10 Male to 4.3-10 Male	3'	L4-HMHM-3-SGW-D	1M	L4-HMHM-1M-SGW-D
	4'	L4-HMHM-4-SGW-D	1.5M	L4-HMHM-1M5-SGW-D
	6'	L4-HMHM-6-SGW-D	2M	L4-HMHM-2M-SGW-D
	8'	L4-HMHM-8-SGW-D	2.5M	L4-HMHM-2M5-SGW-D
	10'	L4-HMHM-10-SGW-D	3M	L4-HMHM-3M-SGW-D
	12'	L4-HMHM-12-SGW-D	4M	L4-HMHM-3M5-SGW-D
	15'	L4-HMHM-15-SGW-D	5M	L4-HMHM-5M-SGW-D
	20'	L4-HMHM-20-SGW-D	6M	L4-HMHM-6M-SGW-D
	25'	L4-HMHM-25-SGW-D	8M	L4-HMHM-8M-SGW-D
	30'	L4-HMHM-30-SGW-D	10M	L4-HMHM-10M-SGW-D



SureFlex Cable Assemblies; Superflexible 1/4-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With superflexible 1/4-Inch FSJ1-50A				
4.3-10 Male to 4.3-10 Male	1'	F1A-HMHM-1-P	1M	F1A-HMHM-1M-P
	2'	F1A-HMHM-2-P	2M	F1A-HMHM-2M-P
	3'	F1A-HMHM-3-P	3M	F1A-HMHM-3M-P
	4'	F1A-HMHM-4-P	4M	F1A-HMHM-4M-P
	5'	F1A-HMHM-5-P	5M	F1A-HMHM-5M-P
	10'	F1A-HMHM-10-P	10M	F1A-HMHM-10M-P
	20'	F1A-HMHM-20-P	20M	F1A-HMHM-20M-P
4.3-10 Male to 4.3-10 Male Right Angle	1'	F1A-HMHR-1-P	1M	F1A-HMHR-1M-P
	2'	F1A-HMHR-2-P	2M	F1A-HMHR-2M-P
	3'	F1A-HMHR-3-P	3M	F1A-HMHR-3M-P
	4'	F1A-HMHR-4-P	4M	F1A-HMHR-4M-P
	5'	F1A-HMHR-5-P	5M	F1A-HMHR-5M-P
	10'	F1A-HMHR-10-P	10M	F1A-HMHR-10M-P
	20'	F1A-HMHR-20-P	20M	F1A-HMHR-20M-P
4.3-10 Male to 7-16 DIN Male	1'	F1A-HMDM-1-P	1M	F1A-HMDM-1M-P
	2'	F1A-HMDM-2-P	2M	F1A-HMDM-2M-P
	3'	F1A-HMDM-3-P	3M	F1A-HMDM-3M-P
	4'	F1A-HMDM-4-P	4M	F1A-HMDM-4M-P
	5'	F1A-HMDM-5-P	5M	F1A-HMDM-5M-P
	10'	F1A-HMDM-10-P	10M	F1A-HMDM-10M-P
	20'	F1A-HMDM-20-P	20M	F1A-HMDM-20M-P

SureFlex Cable Assemblies; Superflexible 1/4-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With superflexible 1/4-Inch FSJ1-50A				
7-16 DIN Male to 7-16 DIN Male Right Angle	1'	F1A-DMDR-1-P	1M	F1A-DMDR-1M-P
	2'	F1A-DMDR-2-P	2M	F1A-DMDR-2M-P
	3'	F1A-DMDR-3-P	3M	F1A-DMDR-3M-P
	4'	F1A-DMDR-4-P	4M	F1A-DMDR-4M-P
	5'	F1A-DMDR-5-P	5M	F1A-DMDR-5M-P
	10'	F1A-DMDR-10-P	10M	F1A-DMDR-10M-P
	20'	F1A-DMDR-20-P	20M	F1A-DMDR-20M-P

D-CLASS SureFlex Cable Assemblies Available:

D-Class Jumpers Order Configuration

F1-HMHM-X-D

D-Class with SureGuard Boot Order Configuration

F1-HMHM-X-SGW-D



**Stock and Return Conditions Apply to All 1/4" and 3/8" Assemblies

SureFlex Cable Assemblies; Superflexible 3/8-Inch Cable

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With superflexible 3/8-Inch FSJ2-50				
4.3-10 Male to 4.3-10 Male	1'	F2A-HMHM-1-P	1M	F2A-HMHM-1M-P
	2'	F2A-HMHM-2-P	2M	F2A-HMHM-2M-P
	3'	F2A-HMHM-3-P	3M	F2A-HMHM-3M-P
	4'	F2A-HMHM-4-P	4M	F2A-HMHM-4M-P
	5'	F2A-HMHM-5-P	5M	F2A-HMHM-5M-P
	10'	F2A-HMHM-10-P	10M	F2A-HMHM-10M-P
	20'	F2A-HMHM-20-P	20M	F2A-HMHM-20M-P
4.3-10 Male to 4.3-10 Male Right Angle	1'	F2A-HMHR-1-P	1M	F2A-HMHR-1M-P
	2'	F2A-HMHR-2-P	2M	F2A-HMHR-2M-P
	3'	F2A-HMHR-3-P	3M	F2A-HMHR-3M-P
	4'	F2A-HMHR-4-P	4M	F2A-HMHR-4M-P
	5'	F2A-HMHR-5-P	5M	F2A-HMHR-5M-P
	10'	F2A-HMHR-10-P	10M	F2A-HMHR-10M-P
	20'	F2A-HMHR-20-P	20M	F2A-HMHR-20M-P
4.3-10 Male to 7-16 DIN Male	1'	F2A-HMDM-1-P	1M	F2A-HMDM-1M-P
	2'	F2A-HMDM-2-P	2M	F2A-HMDM-2M-P
	3'	F2A-HMDM-3-P	3M	F2A-HMDM-3M-P
	4'	F2A-HMDM-4-P	4M	F2A-HMDM-4M-P
	5'	F2A-HMDM-5-P	5M	F2A-HMDM-5M-P
	10'	F2A-HMDM-10-P	10M	F2A-HMDM-10M-P
	20'	F2A-HMDM-20-P	20M	F2A-HMDM-20M-P

continued

SureFlex Cable Assemblies; Superflexible 3/8-Inch Cable *continued*

Description	Cable Length (feet)	Part Number	Cable Length (meters)	Part Number
SureFlex Cable Assemblies With superflexible 3/8-Inch FSJ2-50				
4.3-10 Male to 7-16 DIN Male Right Angle	1'	F2A-HMDR-1-P	1M	F2A-HMDR-1M-P
	2'	F2A-HMDR-2-P	2M	F2A-HMDR-2M-P
	3'	F2A-HMDR-3-P	3M	F2A-HMDR-3M-P
	4'	F2A-HMDR-4-P	4M	F2A-HMDR-4M-P
	5'	F2A-HMDR-5-P	5M	F2A-HMDR-5M-P
	10'	F2A-HMDR-10-P	10M	F2A-HMDR-10M-P
	20'	F2A-HMDR-20-P	20M	F2A-HMDR-20M-P
7-16 DIN Male to 7-16 DIN Male Right Angle	1'	F2A-DMDR-1-P	1M	F2A-DMDR-1M-P
	2'	F2A-DMDR-2-P	2M	F2A-DMDR-2M-P
	3'	F2A-DMDR-3-P	3M	F2A-DMDR-3M-P
	4'	F2A-DMDR-4-P	4M	F2A-DMDR-4M-P
	5'	F2A-DMDR-5-P	5M	F2A-DMDR-5M-P
	10'	F2A-DMDR-10-P	10M	F2A-DMDR-10M-P
	20'	F2A-DMDR-20-P	20M	F2A-DMDR-20M-P

D-CLASS SureFlex Cable Assemblies Available:

D-Class Jumpers Order Configuration

F2-HMHM-X-D

D-Class with SureGuard Boot Order Configuration

F2-HMHM-X-SGW-D



*Stock and Return Conditions Apply to All 1/4" and 3/8" Assemblies

Plenum cable assemblies *continued*

Part Number	Cable Length (feet)	Part Description
HL4RPV plenum cable assemblies		
H4-HMHM-10-P	10'	HL4-50 Plenum Rated 1/2" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 10'
H4-HMHM-20-P	20'	HL4-50 Plenum Rated 1/2" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 20'
H4-HMHM-30-P	30'	HL4-50 Plenum Rated 1/2" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 30'
H4-HMHM-40-P	40'	HL4-50 Plenum Rated 1/2" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 40'
H4-HMHM-50-P	50'	HL4-50 Plenum Rated 1/2" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 50'
H4-NMNM-10-P	10'	HL4-50 Plenum Rated 1/2" Cable Assembly (N Type male / N Type male) 10'
H4-NMNM-20-P	20'	HL4-50 Plenum Rated 1/2" Cable Assembly (N Type male / N Type male) 20'
H4-NMNM-30-P	30'	HL4-50 Plenum Rated 1/2" Cable Assembly (N Type male / N Type male) 30'
H4-NMNM-40-P	40'	HL4-50 Plenum Rated 1/2" Cable Assembly (N Type male / N Type male) 40'
H4-NMNM-50-P	50'	HL4-50 Plenum Rated 1/2" Cable Assembly (N Type male / N Type male) 50'
H4-NMNM-60-P	60'	HL4-50 Plenum Rated 1/2" Cable Assembly (N Type male / N Type male) 60'
PTS1 plenum cable assemblies		
PTS1P-HMHM-10-P	10'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 10'
PTS1P-HMHM-20-P	20'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 20'
PTS1P-HMHM-30-P	30'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 30'
PTS1P-HMHM-40-P	40'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 40'
PTS1P-HMHM-50-P	50'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 50'
PTS1P-NMNM-10-P	10'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (N Type male / N Type male) 10'
PTS1P-NMNM-20-P	20'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (N Type male / N Type male) 20'
PTS1P-NMNM-30-P	30'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (N Type male / N Type male) 30'
PTS1P-NMNM-40-P	40'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (N Type male / N Type male) 40'
PTS1P-NMNM-50-P	50'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (N Type male / N Type male) 50'
PTS1P-NMNM-60-P	60'	PTS1-50-P Plenum Rated 1/4" Cable Assembly (N Type male / N Type male) 60'

continued

Plenum cable assemblies *continued*

Part Number	Cable Length (feet)	Part Description
PTS2 Plenum cable assemblies		
PTS2P-HMHM-10-P	10'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 10'
PTS2P-HMHM-20-P	20'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 20'
PTS2P-HMHM-30-P	30'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 30'
PTS2P-HMHM-40-P	40'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 40'
PTS2P-HMHM-50-P	50'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (Type 4.3-10 male / 4.3-10 male) 50'
PTS2P-NMNM-10-P	10'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (N Type male / N Type male) 10'
PTS2P-NMNM-20-P	20'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (N Type male / N Type male) 20'
PTS2P-NMNM-30-P	30'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (N Type male / N Type male) 30'
PTS2P-NMNM-40-P	40'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (N Type male / N Type male) 40'
PTS2P-NMNM-50-P	50'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (N Type male / N Type male) 50'
PTS2P-NMNM-60-P	60'	PTS2-50-P Plenum Rated 3/8" Cable Assembly (N Type male / N Type male) 60'

HELIAX® Connectors

Model Number Nomenclature Chart

¹F4 - ²* - ³HM - ⁴D

Cable Compatibility Indicator

1	F4	FSJ4-50B SUPERFLEX 1/2"
	L4	LDF4-50A STANDARD FLEX 1/2"
	ALF	AVA5-50
	A5	AVA5-50, AVA5-50FX
	AL6, A6	FIRE RETARDANT LDF4
	78	7/8" COAX
	114	1 1/4" COAX
	158	1 5/8" COAX
	F1	FSJ1-50A SUPERFLEX 1/4"
	F2	FSJ2-50 SUPERFLEX 3/8"
	L1	LDF1-50 STANDARD FLEX 1/4"
	L2	LDF2-50 STANDARD FLEX 3/8"

Wildcard A

2	EZ	EZ FIT
	B	BULKHEAD FEMALE
	P	PLATED (OLD NOMENCLATURE)
	T	TRI-METAL PLATED (OLD NOMENCLATURE)

Length (M/Ft): Examples

3	HM	4.3-10 STRAIGHT MALE
	HR	4.3-10 RIGHT ANGLE MALE
	DM	7-16 DIN STRAIGHT MALE
	DR	7-16 DIN RIGHT ANGLE MALE
	KM	4.1-9.5 DIN STRAIGHT MALE
	HF	4.3-10 STRAIGHT FEMALE
	DF	7-16 DIN STRAIGHT FEMALE

Wildcard B

4	-D	D-CLASS
	-PSA OR -PS	POSITIVE STOP
	-C	CAPTIVATED CENTER CONTACT
	-H	HEX COUPLING NUT
	-HC	HEX COUPLING NUT CAPTIVATED CENTER CONTACT
	-BH	BULKHEAD FEMALE
	-BHC	BULKHEAD FEMALE CAPTIVATED CENTER CONTACT

Example: F4HM-D
F4 = FITS FSJ4 cable
H = 4.3-10 interface
M = Male
-D = D-CLASS series

50 Ohm Connectors

Cable Size	Cable Type	Connector Type	Connector Part Number	Cable Prep Tool Used	Coupling Nut Torque Tool Used
50 Ohm Connectors					
1/2"	Standard; LDF4-50A	4.3-10 Male	L4HM-D	CPT-L4-D	TW-4310
		7-16 DIN Male	L4TDM-PSA	CPT-12U	244377
		7-16 DIN Female	L4TDF-PSA		244377
		7-16 DIN Male, Right Angle	L4DR-PS		244377
		N Male	L4TNM-PSA		244379
		N Female	L4TNF-PSA		244379
	Superflexible; FSJ4-50B	4.3-10 Male	F4HM-D	CPT-F4-D	TW-4310
		7-16 DIN Male	F4PDMV2-C	CPT-F4B	244377
		7-16 DIN Female	F4PDF-C		244377
		7-16 DIN Male, Right Angle	F4DR-C		244377
		N Male	F4PNMV2-HC		244379
		N Female	F4PNF-C		244379
5/8"	Standard; LDF4.5-50	7-16 DIN Male	L4.5PDM-RC	CPT-L45RC	244377
		N Male	L4.5PNM-RC		244379
		N Female	L4.5PNF-RC		244379
7/8"	AVA5-50 or AVA5-50FX	4.3-10 Male	A5HM-D	MCPT-A5-D	TW-4310
		4.3-10 Female	A5HF-D		TW-4310
	AVA5-50 Only	7-16 DIN Male	A5DM-D		244377
		7-16 DIN Female	A5DF-D		244377
		N Male	A5NM-S		244379
		N Female	A5NF-S		244379
		7-16 DIN Male	AL5DM-PSA	CPT-78U	244377
		7-16 DIN Female	AL5DF-PSA		244377
		N Male	AL5NM-PSA		244379
		N Female	AL5NF-PSA		244379
		7-16 DIN Female	78EZDF	A5FX-EZPT	244377
	LDF5-50A Note: this cable is obsolete	4.3-10 Male	L5HM-S	MCPT-L5-S	TW-4310
		4.3-10 Female	L5HF-S	MCPT-L5-S	TW-4310



AL7DF-PSA
EXAMPLE
CONNECTOR

continued

50 Ohm Connectors *continued*

Cable Size	Cable Type	Connector Type	Connector Part Number	Cable Prep Tool Used	Coupling Nut Torque Tool Used
50 Ohm Connectors <i>continued</i>					
1-1/4"	Standard; AVA6-50	7-16 DIN Male	AL6DM-PSA	CPT-114U	244377
		7-16 DIN Female	AL6DF-PSA	CPT-114U	244377
		4.3-10 Female	A6HF-S	MCPT-114158-S	TW-4310
		4.3-10 Male	A6HM-S	MCPT-114158-S	TW-4310
		7-16 DIN Male	114EZDM	A6-EZPT	244377
		7-16 DIN Female	114EZDF	A6-EZPT	244377
		N type Male	114EZNM	A6-EZPT	244379
		N type Female	114EZNF	A6-EZPT	244379
1-5/8"	Standard AVA7-50 section	7-16 DIN Male	AL7DM-PSA	CPT-158U	244377
		7-16 DIN Female	AL7DF-PSA		244377
		N Male	AL7NM-PSA		244379
		N Female	AL7NF-PSA		244379
		4.3-10 Female	A7HF-S	MCPT-114158-S	TW-4310
		4.3-10 Male	A7HM-S	MCPT-114158-S	TW-4310
		7-16 DIN Male	158EZDM	A7-EZPT	244377
		7-16 DIN Female	158EZDF	A7-EZPT	244377
		N type Male	158EZNM	A7-EZPT	244379
		N type Female	158EZNF	A7-EZPT	244379

continued

50 Ohm Connectors *continued*

Cable Size	Cable Type	Image	Connector Type	Connector Part Number	Cable Prep Tool Used	Coupling Nut Torque Tool Used
50 Ohm Connectors <i>continued</i>						
1/4"	Superflexible; FSJ1-50A		4.3-10 Male	F1HM-D	NA	NA
			4.3-10 Male Right Angle	F1HR-D		
			4.3-10 Male Push-Pull	F1HMP-D		
			7-16 DIN Male	F1TDM-C		
			7-16 DIN Female	F1TDF		
	Standard; LDF1-50		4.3-10 Male	L1HM-D		
			7-16 DIN Male	L1TDM-PL		
			7-16 DIN Female	L1TDF-PL		
3/8"	Superflexible; FSJ2-50		4.3-10 Male	F2HM-D		
			4.3-10 Male Right Angle	F2HR-D		
	Standard; LDF2-50		4.3-10 Male	L2HM-D		
			7-16 DIN Male	L2TDM-PL		
			7-16 DIN Female	L2TDF-PL		
			7-16 DIN Male, Right Angle	L2PDR-C		

Tools

Description	Used with Cable Type	Connector Type	Part Number
Manual Cable Preparation Tools Prepares coaxial cable for connector attachment	1/4" cable; FSJ4-50B	F4-V2 Series connectors only	MCPT-1412
	1/2" cable; LDF4-50A	LDF4 Positive Stop® (-PS & -PSA) only	MCPT-L4
	7/8" cable; AVA5-50/ AVA5-50FX	A5 Series connectors only	MCPT-A5-D
	1 1/4" cable AVA6-50	A6 -S eries	MCPT-114158-S
	1 5/8" cable AVA7-50	A7 -S eries	MCPT-114158-S
Automated Cable Preparation Tools Used with standard drill to prepare coaxial cable for connector attachment	1/2" cable; LDF4-50A	LDF4 Positive Stop (-PS & -PSA) only	CPT-12U
		LDF4 Connectors ending in -D only	CPT-L4-D
	1/2" cable; FSJ4-50B	F4-V2 Series connectors only	CPT-F4B
		FSJ4 Connectors ending in -D only	CPT-F4-D
	1-1/4" cable; AVA6-50	114 EZfit Series connectors only	A6-EZPT
EZfit® Manual Cable Preparation Tools	1-5/8" cable; AVA7-50	158 EZfit Series connectors only	A7-EZPT
	7/8" cable; AVA5-50	78 EZfit Series connectors only	78-HPT
EZfit Automated Cable Preparation Tools	7/8" cable; AVA5-50/ AVA5-50FX	EZfit Series connectors only	A5FX-EZPT
	1-1/4" cable; AVA6-50	114 EZfit Series connectors only	A6-EZPT
	1-5/8" cable; AVA7-50	158 EZfit Series connectors only	A7-EZPT


Manual Tool
(MCPT-1412)

Automatic Tool
(CPT-)

Tightening Tool
(TT-4310)

Torque Wrench
(TW-4310)

Description	Used with Connector Type	Part Number
Connector Torque Tools		
Coupling nut tightening tool	SureFlex 4.3-10 straight male jumpers	TT-4310
Torque wrenchs	4.3-10 connectors	TW-4310
	7-16 DIN connectors	244377
	Type N connectors	244379

HELIAX® Surge Arrestor/Bias Tee

Model Number Nomenclature Chart

¹ APTDC - ² DFDM - ³ DB

Arrestor/Bias Tee Indicator

1	ABT	ANDREW BIAS TEE
	APT	ANDREW SURGE ARRESTOR (T-SERIES)
	APG	ANDREW SURGE ARRESTOR (GAS-TUBE)
	ADCB	ANDREW DC BLOCK
	APTDC	ANDREW SUREGE ARRESTOR (T-SERIES DC PASSING)

Interfaces Examples:

2	BDFDM	BULKHEAD DIN FEMALE/DIN MALE
	BDFDF	BULKHEAD DIN FEMALE/DIN FEMALE
	DFDF	DIN FEMALE/DIN FEMALE
	DFDM	DIN FEMALE/DIN MALE
	NFNM	N FEMALE/N MALE
	NFNF	N FEMALE/N FEMALE
	BNFNM	BULKHEAD N FEMALE/N MALE
	BNFNF	BULKHEAD N FEMALE/N FEMALE

Wildcard A

3	DB	DUAL BAND
	DBT	DUAL BAND (CYLINDRICAL BODY)
	DBW	DUAL BAND (WIDE)
	090	90V GASTUBE
	350	350V GASTUBE
	ADBA	PASSES AISG 2.1 & DC

*Refer to datasheets for product details

Replacement Blade Kits

Description	Part Number
Replacement Blade Kits For cable preparation tools	
Use with CPT-F4B & CPT-F4-D only	CPT-BKSF4
Use with CPT-12U & CPT-L4-D only	CPT-BK12U
Use with A5FX-EZPT only	BK-A6A7EZPT-JC
Use with A6-EZPT only	BK-A6A7EZPT-JC
Use with A7-EZPT only	BK-A6A7EZPT-JC

Protective Cap Kits

Description	Part Number
Protective Cap Kits Male interface, mates on female connector	
4.3-10 female end cap	SMALL-CAPKIT
7-16 DIN female end cap	DF-CAPKIT
4.3-10 Male end cap	Small-M-CAPKIT

Surge Arrestors

Description	Part Number
Dual Band Bias Tee Surge Arrestors	
DIN-F/DIN-M	ABT-DFDM-ADBH
DIN-M/DIN-F	ABT-DMDF-ADBH
Arrestor Plus® LTE Band Quarterwave Surge Arrestor	
DIN-F Bulkhead/DIN-M	APTDC-BDFDM-DB



SMALL-CAPKIT

Grounding Kits

Description	Grounding Lead Wire	Lug	Part Number
Grounding Kits			
For 1/4" and 3/8" Coaxial Cable	24"	Attached	223158-2
For 1/2" Coaxial Cable	24"	Attached	SG12-06B2A
	48"	Field Attach	SG12-12B2U
For 7/8" Coaxial Cable	24"	Attached	SG78-06B2A
	48"	Field Attach	SG78-12B2U
For 1-1/4" Coaxial Cable	24"	Attached	SG114-06B2A
	48"	Field Attach	SG114-12B2U
For 1-5/8" Coaxial Cable	24"	Attached	SG158-06B2A
	48"	Field Attach	SG158-12B2U
Universal Grounding Kit For 1/2" through 1-5/8" corrugated and smoothwall coaxial cable, elliptical waveguide 63 through 180 and FiberFeed Hybrid cables			UG12158-15B4-T
Small Universal Grounding Kit			GK-SUNV



Hangers

Description	Part Number
Butterfly Hanger (10 pieces)	
For 7/8" coaxial cable and elliptical waveguide 85 and 90	42396A-5
For 1/2" or 3/8" coaxial cable and elliptical waveguide 180, 220, and 240	43211A
For 1 1/4" coaxial cable	423964-1
For 1 5/8" coaxial cable and EW-64 wave guide	423964-2
Single click-on hanger kit (1 each)	
Click-on hanger kits with hardware (1 ea)	
1/2" Single click-on hanger kits with hardware 3 stack (1 ea)	SHK-12-3-P
7/8" Single click-on hanger kits with hardware 3 stack (1 ea)	SHK-78-3-P
1 1/4" Single click-on hanger kits with hardware 3 stack (1 ea)	SHK-114-3-P
1 5/8" Single click-on hanger kits with hardware 3 stack (1 ea)	SHK-158-3-P
SnapStak® Hanger (10 pieces)	
For 1/2" coaxial cable	SSH-12
For 7/8" coaxial cable	SSH-78
For 1-1/4" coaxial cable	SSH-114
For 1-5/8" coaxial cable	SSH-158
For 36-51mm Hybrid power and coaxial cables	SSH-XL



Single Block
Hanger
(BHS-114)



SnapStak Hanger
(SSH-12)



Butterfly Hanger
(42396A-5)

Installation Accessories and Tools

Description	Part Number
Adapters	
Angle, standard 3/8" tapped hole	31768A
Angle, universal snap-in, 3/4" hole	UA-3
3-way snap-in, stand-off for 2"-3" round members	STS3-23
3-way, stand-off for 1.5"-3" round members	TTS3-153
SnapSeal™ Entry Cushions	
4 holes for 1/2" coaxial cable	SEC-412
3 holes for 7/8" coaxial cable	SEC-378
1 hole for 1-5/8" coaxial cable	SEC-1158
Lace-Up Hoisting Grips	
For 7/8" coaxial cable, elliptical waveguide 77, and HELIAX FiberFeed Hybrid cable	19256B
For 1-5/8" coaxial cable and elliptical waveguide 44, 52, and 63	24312A
For 1/2" coaxial cable	43094
for 1 1/4" coaxial cable	29961
Support Hoisting Grips	
For 1/2" cable	L4SGRIP
For 7/8" coaxial cable	L5SGRIP
For 1-1/4" coaxial cable	L6SGRIP
For 1-5/8" coaxial cable	L7SGRIP
Tape and Weatherproofing Kit	
Black self-fusing tape, 15 feet	FT-TB
Weatherproofing kit for connectors and splice Includes (6) 2-1/2" butyl rubber rolls and (2) 3/4" and (1) 2" PVC tape rolls	221213


Adapter
(UA-3)

Adapter
(STS3-23)

SnapSeal Entry Cushions
(SEC-378)

Lace-Up Hoisting Grip
(19256B)

Support Hoisting Grip
(L5SGRIP)


Weatherproofing Kit
(221213)

HELIAX RF – Coaxial Cable

CommScope offers a full portfolio Indoor Riser & Plenum, and Outdoor Cables

- Riser identified with RK nomenclature and ETL CMR Rating
- Plenum identified with RPV nomenclature and ETL CMP Rating
- CommScope connectors- Compatible with Indoor and Outdoor cables
- FXL-780, AVA5-50FX, and AVA5RK-50FX are not available in North America.

Description	Part Number
Feeders 7/8"- 1 5/8"	AVA5-50, AVA5RK-50, AVA5-50FX, AVA5RK-50FX, AVA6-50 AVA6-50, AVA6RK-50, AVA7-50 AVA7RK-50
Smoothwall Feeders 7/8"	FXL-780 (Not available in North America)
½" Feeder/Jumper	LDF4-50A, LDF4RK-50A, FSJ4-50B, FSJ4RK-50B
3/8" Feeder/Jumper	LDF2-50, LDF2-RK, FSJ2-50, FSJ2RK-50
1/4" Feeder/Jumper	LDF1-50, LDF1RK-50, FSJ1-50A, FSJ1RK-50B
1/2" Plenum	HL4RPV-50 (Copper)
1/2" Plenum	AL4RPV-50 (Aluminum)
1/2" Plenum	HL4RPV-50B (Blue Jacket)
1/4" Plenum	PTS1-50-P (Plenum)
3/8" Plenum	PTS2-50-P (Plenum)

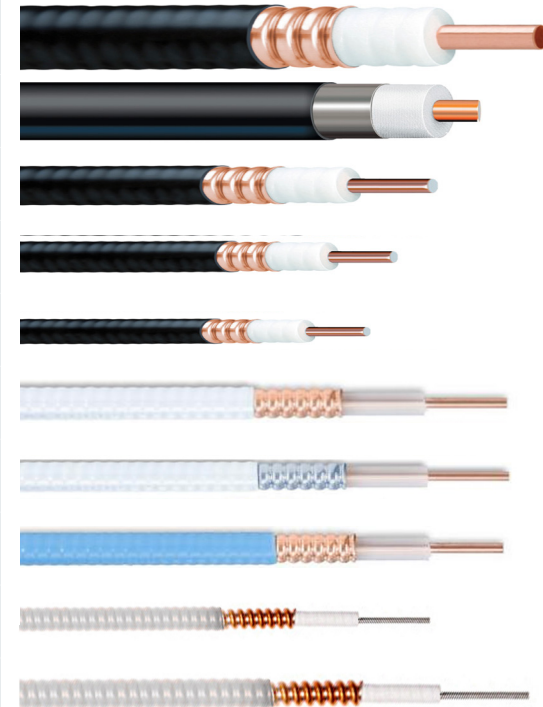

Model Number Nomenclature Chart

1 2 3 4 5
FSJ 4 RK - 50 - **

Cable Type

1	FSJ	SUPERFLEX
	LDF	STANDARD FLEX (LOW DENSITY FOAM)
	AVA	FEEDER (ANDREW VIRTUAL AIR)
	AL	PLENUM (ALUMINUM)
	HL	PLENUM (COPPER)

Size: Examples

2	1	1/4 INCH
	2	3/8 INCH
	4	1/2 INCH
	5	7/8 INCH
	6	1-1/4 INCH
	7	1-5/8 INCH

Wild Card A: Examples

3	RK, RN	FIRE RETARDANT, ZERO HALOGEN RISER
	RPV	FIRE RETARDANT, PLENUM
	P	PREMIUM LOW VSWR

Ohms

4	50	50 OHMS
	75	75 OHMS

Wildcard B

5	-42	LOW VSWR (450-680, 680-800, 806-960, 1700-2200 MHz)
	-43, -43B	LOW VSWR (710-806, 806-970, 1420-1530, 1700-2180, 2535-2655 MHz)
	-NHR	ZERO HALOGEN RISER RATED
	-E1	ERICSSON SPECIAL DETAIL

LDF4-50A

HELIAX® Low Density Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket
Cable manufactured between 1971–Present



Cable size	Connector	Connector status	Replacement	Status	Grounding kit prep tool	Grounding kit tool replacement blade kit	Automated tool	Automated tool blade kits	Manual tool	Blade kits	Flare tool
1/2" LDF4-50A LDF4RK-50A	L4PDM-C	Obsolete	L4TDM-PSA	Active	GKT-L4SG	GBK-SG1278	CPT-L4ARC1 works with listed connectors	CPT-BKS1 CPT-BK12U works with listed connectors	MCPT-L4 works with listed connectors	MCPT-BK4 works with listed connectors	224363 works with listed connectors
	L4TDM-PS	Obsolete	L4TDM-PSA	Active							
	L4TDF-PS	Obsolete	L4TDF-PSA	Active							
	L4PDR-C	Obsolete	L4DR-PS	Active							
	L4PDF-BHC	Active	NA	NA							
	L4TNF-PSA	Active	NA	NA							
	L4TNM-PSA	Active	NA	NA							
	L4HM-D	Active	NA	NA			CPT-L4-D		NA	NA	NA
	L4HMP-D	Active	NA	NA							

Additional notes

- Note only connectors listed in the connector or replacement columns will accommodate the cable
- Positive stop connectors require no special tools or torque wrenches, to tighten the positive connector turn the back nut, not the front body**
- Blade kits are available for the tools contact CommScope
- Positive stop connectors will not accommodate smooth wall aluminium cable

Installation bulletin	Bulletin numbers	Installation bulletin	Bulletin numbers
L4PDM-C	101801	L4DR-PS	237903
L4TDM-PS	7615905	CPT-L4ARC1	237562
L4TDF-PS	237903	MCPT-L4	237647
L4PDR-C	101629	L4HM-D	7719049
L4PDF-BHC	101627	L4HMP-D	7769948
L4TDM-PSA	7615905	CPT-L4-D	237562
L4TDF-PSA	7615905		

FSJ4-50B

FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket
Cable manufactured between 1978–Present



Cable size	Connector	Connector status	Automated tool	Manual tool	Automated tool blade kits	Manual blade kits
1/2" FSJ4-50B FSJ4RK-50B	F4DR-C	Active	CPT-F4B works with listed connectors	MCPT-1412 works with listed connectors	CPT-BKSF4 works with listed connectors	209874 works with listed connectors
	F4NR-HC	Active				
	F4PDF-C	Active				
	F4PDMV2-C	Active				
	F4PNMV2-HC	Active				
	F4PNF-C	Active				
	F4HM-D	Active	CPT-F4-D	NA		NA
	F4HMP-D	Active				

Additional notes


- Note only connectors listed in the connector column will accommodate the cable
- Blade kits are available for the tools contact CommScope
- Check for installation video online
Manual tool: <https://www.youtube.com/watch?v=FhDM-nyXYJk>
Automated tool: <https://www.youtube.com/watch?v=ZxBZD2gfOG4>

Installation bulletin	Bulletin numbers
F4DR-C	237556
F4NR-HC	237556
F4PDF-C	101597
F4PDMV2	237556
F4PNMV2-HC	237554
F4PNF-C	237270

Installation bulletin	Bulletin numbers
CPT-F4B	Bulletin Online
MCPT-1412	237703
Special publication	SP50262-A
F4HM-D	7718500
F4HMP-D	7769947
CPT-F4-D	237562

AVA5-50

AVA5-50, HELIAX® Andrew Virtual Air™ Coaxial Cable, corrugated copper, 7/8 in, black PE jacket
Cable manufactured between 2004–Present

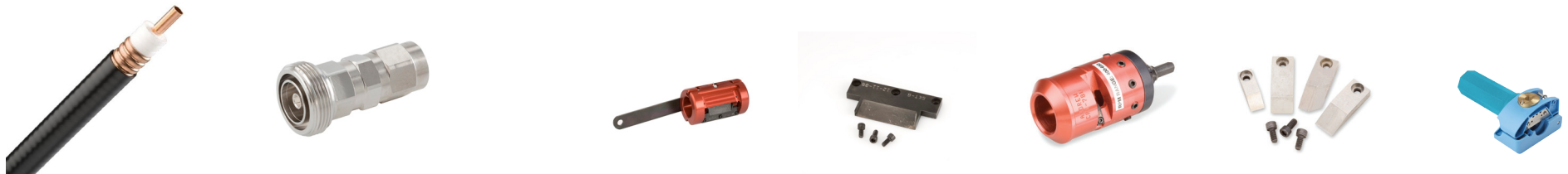

Cable size	Connector	Connector status	Grounding kit prep tool	Grounding kit tool replacement blade kit	Automated tool	Automated tool replacement blade kits	Manual tool
7/8" AVA5-50 AVA5RK-50	78EZDF	Active	GKT-78SG	GBK-SG1278	A5FX-EZPT works with listed connectors	BK-A5FXEZPT-JC	78-HPT works with listed connectors
	78EZDM	Active					
	78EZNM	Active					
	78EZNF	Active					
	A5HF-D	Active			NA	NA	MCPT-A5-D
	A5HM-D	Active					
	A5DF-D	Active					
	A5DM-D	Active					

Additional notes

- Note only connectors listed in the connector column will accommodate the cable
- Check for installation video online
Manual and Automated tools: https://www.youtube.com/watch?v=5_NIDslWBal
- Positive stop connectors will not accommodate AVA5-50FX cable**
- AL5 or L5 connectors will not accommodate AVA5-50FX cable
- EZFIT connectors require a torque wrench—hold the back nut and turn the front**

Installation bulletin	Bulletin numbers
78EZDF	7593458 and 7580829
78EZDM	7593458 and 7580830
78EZNM	7593458 and 7580831
78EZNF	7593458 and 7580832
A5DF-D	7711012
A5DM-D	7711012

AVA6-50

AVA6-50, HELIAX® Andrew Virtual Air™ Coaxial Cable, corrugated copper, 1-1/4 in, black PE jacket
Premium cable
Cable manufactured between 2004–Present



Cable size	Connector	Connector status	Grounding kit prep tool	Grounding kit tool replacement blade kit	Automated tool	Automated tool blade kits	Manual tool
1 1/4" AVA6-50 AVA6RK	AL6DF-PSA	Active	GKT-114SG	GBK-SG114158	CPT-114U works with listed connectors	CPT-BK6 works with listed connectors	NA
	AL6DM-PSA	Active					
	114EZDF	Active					
	114EZDM	Active					
	114EZNM	Active					
	114EZNf	Active					
	A6HM-S	Active					
	A6HF-S	Active					
					A6-EZPT works with listed connectors	BK-A6A7EZPT-JC	
					NA	NA	MCPT-114158-S

Additional notes

- Note only connectors listed in the connector column will accommodate the cable
- Positive stop connectors require no special tools or torque wrenches, to tighten the positive connector turn the back nut, not the front body**
- EZFIT connectors require a torque wrench—hold the back nut and turn the front**

Installation bulletin	Bulletin numbers
AL6DF-PSA	7604922
AL6DM-PSA	7604922
CPT-114U	SP50262-A
114EZDF	7593458 and 7580829
114EZDM	7593458 and 7580829
114EZNM	7593458 and 7580829
114EZNf	7593458 and 7580829
A6DF-S	7717148
A6DM-S	7717148
MCPT-A6A7-S	7717172

AVA7-50

AVA7-50, HELIAX® Andrew Virtual Air™ Coaxial Cable, corrugated copper, 1-5/8 in, black PE jacket

Premium cable

Cable manufactured between 2004–Present



Cable size	Connector	Connector status	Grounding kit prep tool	Grounding kit tool replacement blade kit	Automated tool	Automated tool blade kits	Manual tool
1 5/8" AVA7-50 AVA7RK-50	AL7DF-PSA	Active	GKT-158SG	GBK-SG114158	CPT-158U works with listed connectors	CPT-BK7 works with listed connectors	NA
	AL7DM-PSA	Active					
	AL7NM-PSA	Active					
	AL7NF-PSA	Active			A7-EZPT works with listed connectors	BK-A6A7EZPT-JC	NA
	158EZDF	Active					
	158EZDM	Active					
	158EZNM	Active					
	158EZNF	Active					
	A7HF-S	Active			NA	NA	MCPT-114158-S
	A7HM-S	Active					

Additional notes

- Note only connectors listed in the connector column will accommodate the cable
- Positive stop connectors require no special tools or torque wrenches, to tighten the positive connector turn the back nut, not the front body**
- EZFIT connectors require a torque wrench—hold the back nut and turn the front**

Installation bulletin	Bulletin numbers	Installation bulletin	Bulletin numbers
AL7DF-PSA	7546530	158EZDM	7593458 and 7580829
AL7DM-PSA	7546530	158EZNM	7593458 and 7580829
AL7NM-PSA	7546530	158EZNF	7593458 and 7580829
AL7NF-PSA	7546530	A7DF-S	7717149
CPT-158U	SP50262-A	A7DM-S	7717149
158EZDF	7593458 and 7580829	MCPT-A6A7-S	7717172

Fire Retardant Cable Products Portfolio

Part number		Description	Rating
AL4RPV-50-500		AL4RPV-50, HELIAX® Plenum Rated Air Dielectric Coaxial Cable, corrugated aluminum, 1/2 in, off white PVC jacket, 500 feet	Plenum
AL4RPV-50-1000-B		AL4RPV-50, HELIAX® Plenum Rated Air Dielectric Coaxial Cable, corrugated aluminum, 1/2 in, off white PVC jacket, 1000 feet	Plenum
AL4RPV-50-3000		AL4RPV-50, HELIAX® Plenum Rated Air Dielectric Coaxial Cable, corrugated aluminum, 1/2 in, off white PVC jacket, 3000 feet	Plenum
HL4RPV-50		HL4-50, HELIAX® Plenum Rated Air Dielectric Coaxial Cable, corrugated copper, 1/2 in, off white PVC jacket	Plenum
HL4RPV-50-B		HL4-50A, HELIAX® Plenum Rated Air Dielectric Coaxial Cable, corrugated copper, 1/2 in, blue PVDF jacket	Plenum
LDF4RK-50A		LDF4-50, HELIAX® Low Density Foam Coaxial Cable, corrugated copper, 1/2 in, black non-halogenated, fire retardant polyolefin jacket	Riser
FSJ4RK-50B		FSJ4-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/2 in, black non-halogenated, fire retardant polyolefin jacket	Riser
AVA5RK-50		AVA5-50, HELIAX® Andrew Virtual Air™ Coaxial Cable, corrugated copper, 7/8 in, black non-halogenated, fire retardant polyolefin jacket	Riser
AVA6RK-50		AVA6-50, HELIAX® Andrew Virtual Air™ Coaxial Cable, corrugated copper, 1-1/4 in, black , fire retardant polyolefin jacket	Riser
AVA7RK-50		AVA7-50, HELIAX® Andrew Virtual Air™ Coaxial Cable, corrugated copper, 1-5/8 in, black non-halogenated, fire retardant polyolefin jacket	Riser

HELIAX Small Cell Corrugated Cable Products Portfolio

Part number		Description	Rating
PTS1-50-P		1/4" Superflexible High Power, High Temperature, 50 Ohm, white FR-PVC jacket	Plenum
PTS2-50-P		3/8" Superflexible High Power, High Temperature, 50 Ohm, white FR-PVC jacket	Plenum
FSJ1-50A		1/4" Superflexible Low Density Foam, Black PE Jacket	Standard
FSJ2-50		3/8" Superflexible Foam, Black PE Jacket	Standard
LDF1-50		1/4" Low Density Foam, black PE Jacket	Standard
LDF2-50		3/8" Low Density Foam, black PE Jacket	Standard

4.3-10 Cable Products Portfolio

Connector Adapters (Low-PIM)

CommScope PN	Description
TA-DMHF	LOW-PIM ADAPTOR: 7/16 DM TO 4.3-10 FEMALE
TA-NFHF	LOW-PIM ADAPTOR: NF TO 4.3-10 FEMALE
TA-NMHF	LOW-PIM ADAPTOR: N MALE TO 4.3-10 FEMALE
TA-DFHM	LOW-PIM ADAPTOR: 7/16 DF TO 4.3-10 MALE
TA-DMHM	LOW-PIM ADAPTOR: 7/16 DM TO 4.3-10 MALE
TA-DMHM-K	LOW-PIM ADAPTOR: 7/16 DM TO 4.3-10 MALE Hand torque
TA-NFHM	LOW-PIM ADAPTOR: NF TO 4.3-10 MALE
TA-DMDM	Low-PIM adaptor: 7/16 DIN Male to 7/16 DIN Male
TA-NFDM	Low-PIM Adaptor: N Female to 7/16 DIN Male
TA-DFDR	Low-PIM Adaptor: 7/16 DIN Female to 7/6 DIN Right Male

Connectors (Field Fit)

CommScope PN	Description
F4HM-D	CONNECTOR: FSJ4-50 4.3-10 STRAIGHT MALE
L4HM-D	CONNECTOR: LDF4-50 4.3-10 STRAIGHT MALE
A5HF-D	CONNECTOR: AVA5-50 & AVA5-50FX 4.3-10 STRAIGHT FEMALE
A5HM-D	CONNECTOR: AVA5-50 & AVA5-50FX 4.3-10 STRAIGHT MALE
L5HM-S	CONNECTOR: LDF5 4.3-10 STRAIGHT MALE
L5HF-S	CONNECTOR: LDF5 4.3-10 STRAIGHT FEMALE
A6HF-S	CONNECTOR: AVA6-50 4.3-10 STRAIGHT FEMALE
A6HM-S	CONNECTOR: AVA6-50 4.3-10 STRAIGHT MALE
A7HF-S	CONNECTOR: AVA7-50 4.3-10 STRAIGHT FEMALE
A7HM-S	CONNECTOR: AVA7-50 4.3-10 STRAIGHT MALE

Connectors (Field Fit) *continued*

F1HM-D	*check with CommScope for availability
F1HR-D	
F2HM-D	
F2HR-D	

Tools and Accessories

CommScope PN	Description
SMALL-M-CAPKIT	Male End Cap Assembly for 4.3-10 series and 4.1-9.5 Din, work torque 5-8N/M
SMALL-CAPKIT	Female End Cap Assembly for 4.3-10 series and 4.1-9.5 Din, work torque 5-8N/M
TT-4310	Low-Profile polymer 4.3-10 tightening/torque tool for small spaces
TW-4310	Standard torque wrench 4.3-10
CPT-L4-D	Automated cable preparation tool (compatible with L4HM-D connectors)
CPT-F4-D	Automated cable preparation tool (compatible with F4HM-D connectors)
MCPT-A5-D	Manual cable preparation tool (compatible with A5HF-D, A5HM-D)
MCPT-114158-S	Manual cable preparation tool (compatible with A6HF/HM-D & A7HF/HM-D)

HELIAX® Wireless Connector Video links

QR Code	Cable	Connector
---------	-------	-----------



AL4RPV-50

[Positive Stop™ Series
Manual Prep Tool](#)


FSJ4-50B

[F4 Series Version 2
Manual Prep Tool](#)


FXL-540

[EZfit® Series Version
Manual Prep Tool](#)


FXL-540

[EZfit® Series Version 2
Manual Prep Tool](#)


RCT4

[Positive Stop™ Series
Manual Prep](#)

QR Code	Cable	Connector
---------	-------	-----------



AL4RPV-50

[Positive Stop™ Series
Automated Prep Tool](#)


FSJ4-50B

[F4 Series Version 2
Automated Prep Tool](#)


FXL-540

[EZfit® Series Version
Automated Prep Tool](#)


FXL-540

[EZfit® Series Version 2
Automated Prep Tool](#)


RCT5

[Positive Stop™ Series
Manual Prep](#)

HELIAX® Wireless Connector Video links

QR Code	Cable	Connector
	RCT6	Positive Stop™ Series Manual Prep

	AVA5	EZfit® Series Manual and Automated Prep Tool
---	------	--

	AVA7	Positive Stop™ Series Manual Prep Tool
---	------	--

	AVA7	Positive Stop™ Series Manual Prep
---	------	---

QR Code	Cable	Connector
	RCT7	Positive Stop™ Series Manual Prep

	FXL-780	EZfit® Series Manual and Automated Prep Tool
--	---------	--

	AVA7	Positive Stop™ Series Automated Prep Tool
--	------	---

	4.3-10 SureGuard	4.3-10 Sureguard Installation
--	------------------	---

CommScope E-catalog

Related Resources

[CommScope Transmission line systems](#)

[4.3-10 Web Landing Page](#)

[HELIAX® Cable, Connector, and Tool Matrix](#)

[D-CLASS Jumpers Brochure](#)

[4.3-10 D-CLASS Field Fit connectors Product News Flash](#)


[4.3-10 White Paper](#)

[4.3-10 Series Ecosystem Brochure](#)

[Small sized 4.3-10 jumper Product News Flash](#)

[4.3-10 Video \(YouTube\)](#)

[SureGuard Generation 2.0 Product News Flash](#)

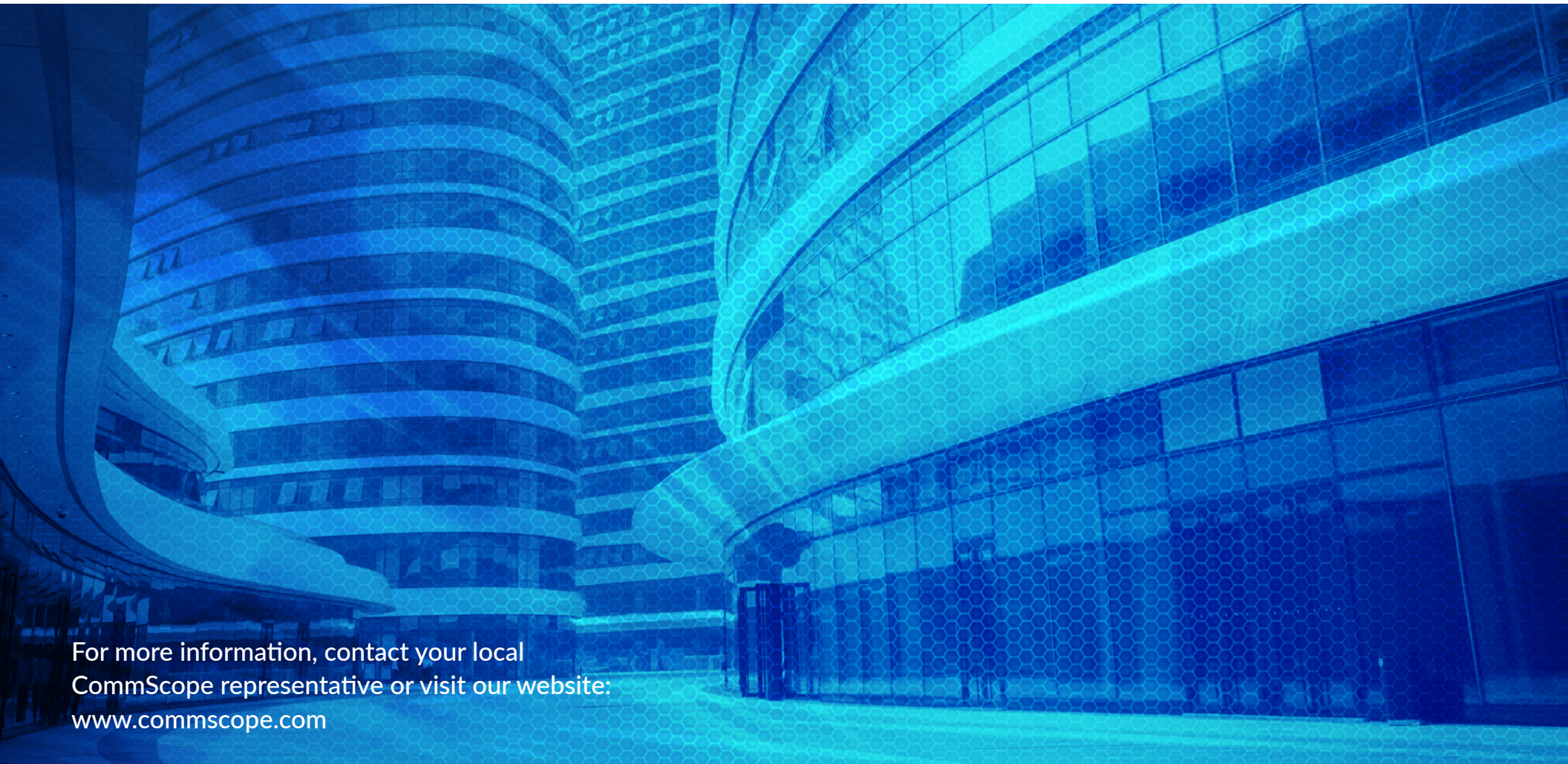

For more information, contact your local
CommScope representative or visit our website:
www.commscope.com