


# 760244708

---

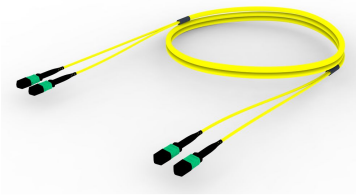

Low Tolerance length Singlemode MPO (Female) to MPO (Female) trunk, 24-Fiber, Low Smoke Zero Halogen B2ca, 325MT

## Product Classification

<b>Regional Availability</b>	Europe   Middle East/Africa
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, boot B</b>	Black
<b>Color, connector A</b>	Green
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Fibers per Subunit, quantity</b>	12
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Female
<b>Interface, Connector B</b>	MPO-12/APC Female
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B (LL)
<b>Total Fibers, quantity</b>	24

## Dimensions

<b>Breakout Length</b>	33 in
<b>Cord Length</b>	325 m   1,066.273 ft
<b>Cable Assembly Length Tolerance</b>	+1/-0 ft

# 760244708

---

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A1, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser

## Included Products

- 760239612 – TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber subunits
- N-024-MP-8W-F12YL/B2
- 860366137 – MPO12, LOW LOSS, FEMALE, Singlemode, GREEN, 3mm