



OFDC-A4 Fiber Optic Splice Closure, gel cable sealing, 1x12 fiber tray Mobra NBN

- Advanced gel sealing technology ensures fast and easy field handling without a need for special tools
- Individual access to drop cable connection area and separate zones for looped cable storage for micro-sheet cables only
- Compact and modular design suited for wraparound drop cable installation, enabling faster deployments
- Allows easy pass-through cabling and integration of optical components, even at later deployment stages

Product Classification

Regional Availability	Australia/New Zealand
Product Type	Single-ended, rectangular fiber closure
Product Series	OFDC


General Specifications

Cable Sealing Type	Compressed gel
Color	Black
Mounting	Manhole Pedestal Strand Wall

Dimensions

Height	70 mm 2.756 in
Width	94 mm 3.701 in
Length	211 mm 8.307 in

Ordering Tree

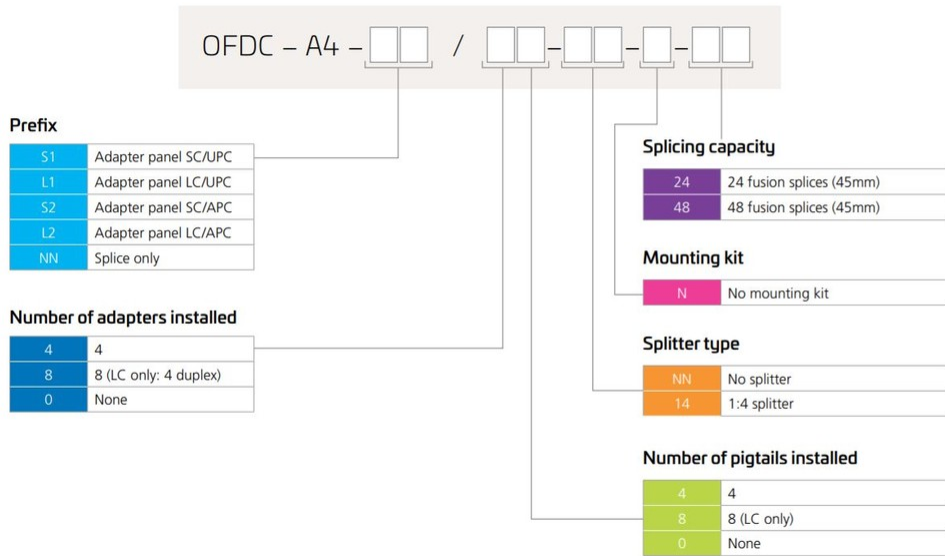

Material Specifications

Material Type Rugged polymer

Environmental Specifications

Installation temperature -5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity 93%, non-condensing
Environmental Space Above ground | Below ground
Qualification Standards IEC 60529, IP68 + 2 m waterhead
UV Resistance UV stabilized

Packaging and Weights

Packaging quantity 1
Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

